


Grey Thermoplastic Rubber Trolley Wheel 60mm, 50kg

Thermoplastic rubber-tyred wheel

PRODUCT

Article number

325-200-060L10

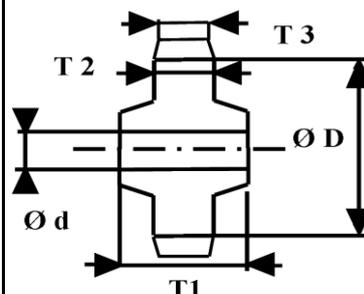

Product Details

Wheel Rim : made of grey impact-resistant polypropylene.

Tread : grey thermoplastic rubber, integrated type. Non-marking.

Hub : symmetrical with plain bore.

Specifications

Wheel Diameter - $\text{ØD} \pm 1\%$	60 mm
Hub Type	Plain
Hub Length T1	28 mm ± 1
Width of Tread T2	24 mm ± 1
Width of Tread-on floor T3	24 mm ± 1
Axle Hole Ø d	$\text{Ø } 10 \text{ mm}$
Hardness of tread A ± 3	A 87° Shore
Load capacity	50 Kg
Temperature	-10 / +50 °C
Weight	0,06 kg

TECHNICAL DATA

Applications :

Quiet and non-marking materials handling.

Lightweight, low starting effort.

Suitable for all interiors floors (warehouses, offices, shops, kitchens,...).