

Product Datasheet model uvex ultrashield 9122 880

**UVEX ARBEITSSCHUTZ GMBH, Würzburger Str. 181-189,
D-90766 Fürth**

1. Product Characteristics

- extremely sporty safety spectacles, ideal for fashion-conscious wearers
- very large lens design for an unrestricted, wide field of vision and increased safety
- soft-grip temple ends provide a comfortable, secure fit without pressure
- soft, adjustable nose pad allows spectacles to be adapted to the wearer to deliver a comfortable, non-slip and pressure-free fit
- robust polycarbonate lens with UV400 – 100% protection against dangerous UV radiation up to 400 nm

2. Technical Details Body

Frame

Material	PC, TPR
Colour	white, black


Marking

Applicable EN ISO norm	16321
Manufacturer 's ID code	W
Impact resistance	C (45 m/s)
Tested under extreme temperatures	T
Conformity symbol	CE

3. Technical Details Lens

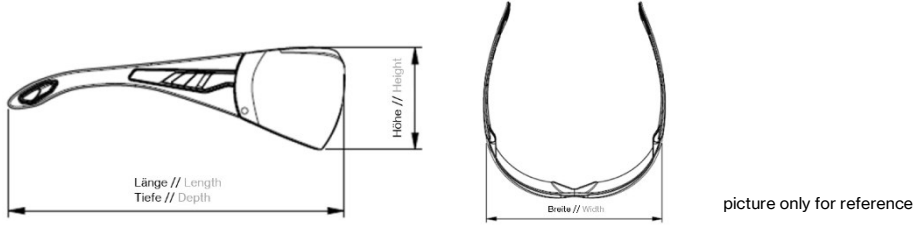
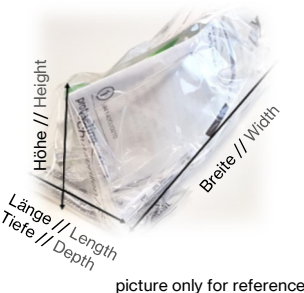
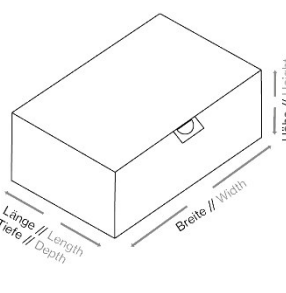
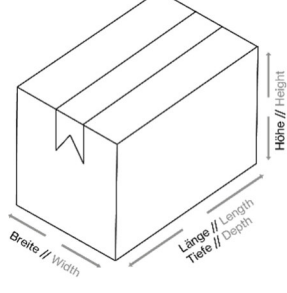
Material	PC
Thickness	2.0 mm at PD
Coating	scratch-resistant, on both sides
Tint	polavision, grey 14%
Features tint	Signal colour recognition Reduction of disturbing surface reflections
UV protection	UV400

Marking

Manufacturer 's ID code	W
Filter	G3
Impact resistance	C (45 m/s)
Tested under extreme temperatures	T
Optical class	1
Conformity symbol	CE
Factory symbol	

4. Logistical Information

Product

Weight	33g		
Dimensions (L x W x H) in approx. mm			
	172 x 151 x 57		
	Packing unit 1	Packing unit 2	Packing unit 3
EAN Code	4066853052029	4066853052036	4066853052043
Quantity in pcs.	1	8	128
Dimensions (L x W x H) in approx. mm			
	127 x 267 x 60	185 x 290 x 97	600 x 400 x 400
Net weight in approx. g	33	164	4,224
Gross weight in approx. g	49	495	8,056
Country of Origin	Taiwan		

5. Miscellaneous

Standards	EN ISO 16321-1
PPE Category	Category II