






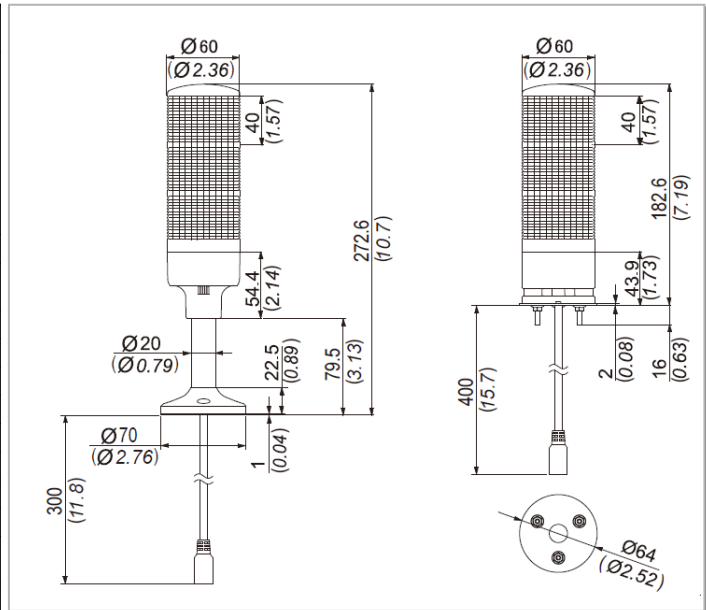
EZ Tower Light

Specifications

	Tube mounting with fixing plate	Base mounting
		
Model	PFXZCETWHA1	PFXZCETWW1
Supported software	GP-Pro EX Ver.3.0.1 or later	
Units	3	
Color	Red /Green /Blue / Yellow	
Light mode	Off /On / Blink (High) / Blink (Low)	
Buzzer	4 sounds	
Buzzer volume	High / Middle / Low	
Buzzer tone	High / Low	
Buzzer sounds	85dB	82dB
Interface	USB2.0 (miniB)	
Rated input voltage	DC5V (Powered from USB bus) *1	
Power consumption	2W *1	
Operating temperature	0 to 55°C (32 to 131 °F)	
Operating humidity	35 to 80%RH (no condensation)	
Operable atmosphere	No corrosive gas	
Storage temperature	-30 to 70°C (-31 to 158 °F)	
Protection	IP54	
Weight	300g (0.66lb)	
Supported standards and regulations	  	

External Dimensions

mm (in.)



*1 In case to connect with GP4000M, need external power supply for USB port.