


push-in T-connector NPQM-T-Q10-S10-P10

Part number: 558794

FESTO

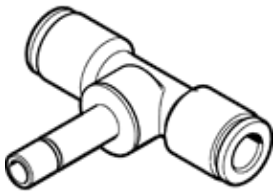

Data sheet

Feature	Value
Size	Standard
Nominal size	8.5 mm
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 70 °C
Product weight	41 g
Pneumatic connection, port 1	Push-in sleeve QS-10
Pneumatic connection, port 2	For tubing outside diameter 10 mm
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material of tubing seal	NBR