



Connectors > PCB Connectors > Wire-to-Board Connectors > Wire-to-Board Connector Assemblies & Housings > DYNAMIC 1900D REC ASSY CAGE



Connector Product Type: **Connector Assembly**

Connector & Housing Type: **Receptacle**

Connector System: **Wire-to-Board**

Number of Positions: **22**

Centerline (Pitch): **3.5 mm [.137 in]**

[All DYNAMIC 1900D REC ASSY CAGE \(6\)](#)

Features

Product Type Features

Connector Product Type	Connector Assembly
Connector & Housing Type	Receptacle
Connector System	Wire-to-Board
Sealable	No
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	22
Number of Rows	2

Body Features

Primary Product Color	Black
-----------------------	-------

Contact Features

Contact Current Rating (Max)	4.5 A
------------------------------	-------

Termination Features

Termination Method to Wire & Cable	Clamp
------------------------------------	-------

Mechanical Attachment

--	--



Mating Retention	With
Connector Mounting Type	Cable Mount (Free-Hanging)

Housing Features

Centerline (Pitch)	3.5 mm[.137 in]
--------------------	-----------------

Dimensions

Wire Size	24 – 18 AWG
Row-to-Row Spacing	3.3 mm[.129 in]

Usage Conditions

Operating Temperature Range	-30 – 105 °C[-22 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts



TE Part # 1891348-1
EXTRACTION TOOL




TE Part # 2-2013325-1
DYNAMIC 1900D HDR ASSY V-TYPE
22P

Also in the Series | Dynamic 1000 Series



Connector Contacts(40)

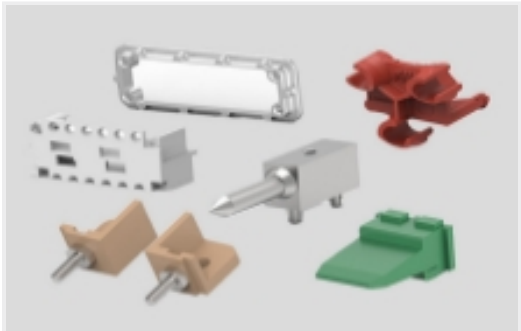

Connector Hardware(3)




Power Contacts(9)



Rectangular Connector Housings(121)



Rectangular Power Connectors(111)

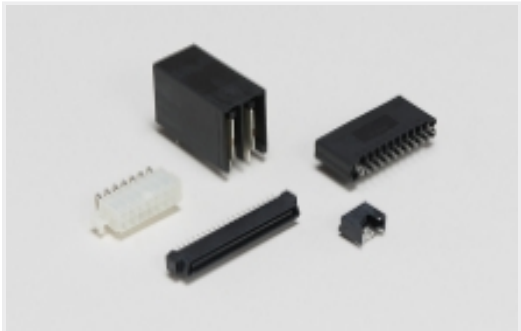

Standard Rectangular Connectors(121)



Wire-to-Board Connector Assemblies
& Housings(33)

Customers Also Bought



TE Part #1-1318115-4
DYNAMIC D-2100 TAB HSG 8P F/H



TE Part #174879-2
1 POS HSG MARK II+



TE Part #1-1903128-7
DYNAMIC 1100D TAB HSG 34P P/M



TE Part #CAT-D9934-A15B
Receptacle and Tab Housing: 2.5 mm
Pitch, 250V



TE Part #3-179554-3
DYNAMIC D-3200 WTW TAB HSG 6P

TE Part #1-2366600-6
DYNAMIC D1000 SLIM TAB HSG 6P X KEY

TE Part #1747500-2
DYNAMIC D4200 TAB CONT L/LP

TE Part #1971239-1
D5200 REC CABLE CLAMP 4P(2ROW) KIT X-X

TE Part #1-174878-1
E-J MK-2 PLUG HSG 1P NATURAL

Documents

Product Drawings

DYNAMIC 1900D REC ASSY CAGE 22p

Japanese

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2-1871940-1_G.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2-1871940-1_G.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2-1871940-1_G.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

DYNAMIC SPRING CLAMP SERIES

English

DYNAMIC SPRING CLAMP SERIES

Japanese

Product Specifications

Product Specification

Japanese



Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

UL Report

English