

 

# pressure regulator LRMA-1/8-QS-8

Part number: 153493  
Product to be discontinued

FESTO

With pressure gauge.

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

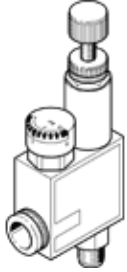

## Data sheet

Feature	Value
Controller function	Output pressure constant with secondary exhaust
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	QS-8
Mounting type	with through hole
Standard nominal flow rate	87 l/min
Inlet pressure 1	0 ... 9 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Actuator lock	Knurled screw with lock nut
Assembly position	Any
Design structure	directly-controlled piston regulator with looped-through compressed air supply
Pressure gauge	with pressure gauge
Pressure regulation range	1 ... 8 bar
Product weight	83.5 g
Material of threaded plug	Brass Nickel plated
Material of threaded seal	PTFE