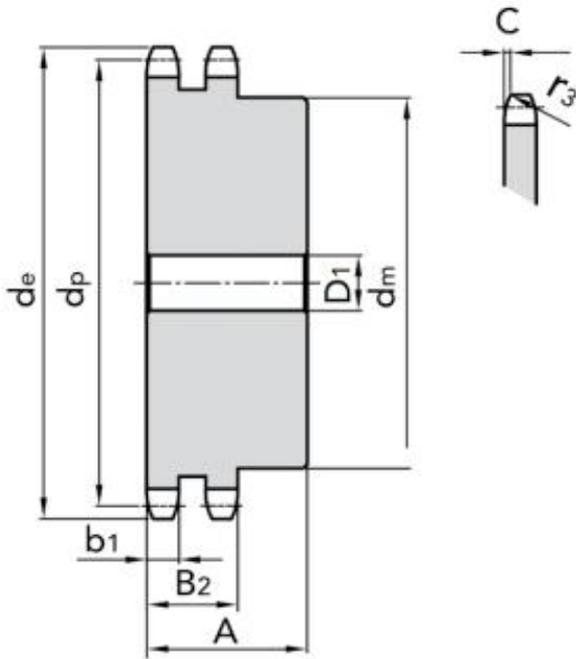


**10212008**

1/2in x 5/16in - Chain sprockets ISO

**2D Technical Drawing**

**Dynamic 3D View**
**Technical Specifications**

Number of teeth (T)	8
de (DE) mm	37.68
dp (DP) mm	33.18
Part number (CODE)	10212008
dm (DM) mm	20
D1 (D1) mm	10
A (A) mm	32
Tooth radius r3 (R3) mm	13
Radius width C (C) mm	1.3
Sprockets tooth width b1 (B1) mm	7
Sprockets tooth width B2 (B2) mm	21
Weight (WEIGHT) kg	0.09
Material (MAT)	STEEL C 45