




Datasheet

RS PRO DC FAN 60x10mm

Stock Number: 789-7860

EN

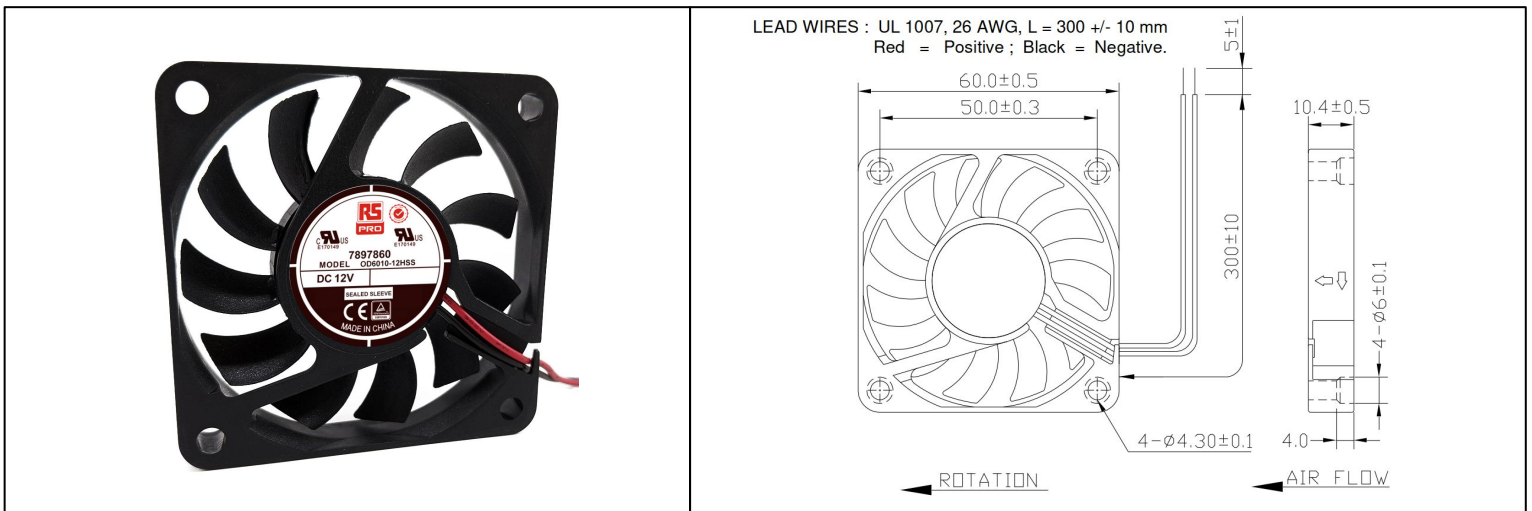

Frame	PBT UL94 V-0 Plastic	<u>Operating Temperature</u> -10°C ~ +70°C <u>Storage Temperature</u> -40°C ~ +70°C <u>Life Expectancy</u> 50,000 hours (L10 at 25°C) Weight: 0.030Kgs (0.06 lbs)	
Impeller	PBT UL94 V-0 Plastic		
Connection	2x Wire Leads, 26 AWG		
Motor	Brushless DC, Auto Cutoff, Auto Restart, Polarity Protected		
Bearing System	Sealed Sleeve		
Dielectric Strength	500VAC/min < 1mA		
Insulation Resistance	10M ohm between leadwire and frame (500VDC)		

Model Number	789-7860
Rated Voltage	12 VDC
Voltage Range	10.8 ~ 13.2
Rated Current	0.25 A
Rated Speed (RPM)	4600
Airflow (CFM)	18.7
Noise Level (dB)	37.6
Max. Static Pressure	0.13" H ₂ O