

## Datasheet


# Buzzer ,12 V dc, 95dB at 1 Metre

RS Stock number




### Specifications:

Supply Voltage:	10-20VDC
Rated Current:	25mA
Decibels at 1 Metre:	95dB
Resonant Frequency:	2900±500Hz
Current Type:	DC
Operating Temperature:	-20°C to +60°C
Storage Temperature:	-30°C to +70°C
Diameter:	43 mm
Colour:	Black
Mounting Style:	Panel Mount
Housing Material	ABS
Application Type:	Buzzer

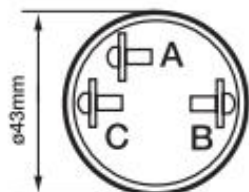**Dimensions:**


Connections for  
115v & 230v  
Tone Terminals  
Pulsed A + B  
Continuous A + C

Connections for  
12v to 48v  
Tone Terminals  
Pulsed B + A  
Continuous B + C

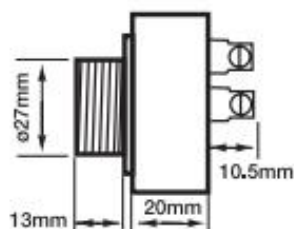

Front View

Dimensions Unit: mm

Tolerance: ±0.5mm