




Sample photo

**Order symbol:** CAB P 806030  
**Product nbr:** 8104308  
**Description:** Polyester cabinet  
**Remarks:** Grey door

**EAN:** 6418074050052  
**El. number:**  
 Finland 3424143  
 Denmark 8212018057  
 Sweden 2539827

**Including:** Cabinet base, door with PUR gasket, 3mm double bit lock(s) with transport and plastic key, screws for mounting plate/DIN-rail and wall fastening lugs with screws. Wall mounting screws not supplied.

Dimensions:		L	W	H	Rating:
mm:		800	600	300	<b>Ingress Protection (EN 60529):</b> IP 66
inch:		31.5	23.6	11.8	<b>Impact Resistance (EN 50102):</b> IK 10
Materials:					
<b>Material:</b>		GRP			
<b>Base colour:</b>		RAL 7032			
<b>Cover colour:</b>		RAL 7032			
<b>Cover screws material:</b>		Stainless steel			
<b>Gasket material:</b>		Polyurethane			
Temperatures:					
<b>Short term:</b>		-50 ... 150 °C			
<b>Continuous:</b>		-40 ... 70 °C			
<b>Short term:</b>		-60 ... 302 °F			
<b>Continuous:</b>		-40 ... 158 °F			
Accessories:					
MP 8060		Mounting plate			
					<b>Electrical insulation:</b> Totally insulated
					<b>UV resistance:</b> UL 508
					<b>Flammability Rating (UL 746 C 5):</b> UL 94 5V
					<b>Glow Wire Test (IEC 695-2-1) °C:</b> 960
					<b>UL Type:</b> UL TYPE 3, 3R, 3S, 4, 4X, 12, 13
Certificates:					

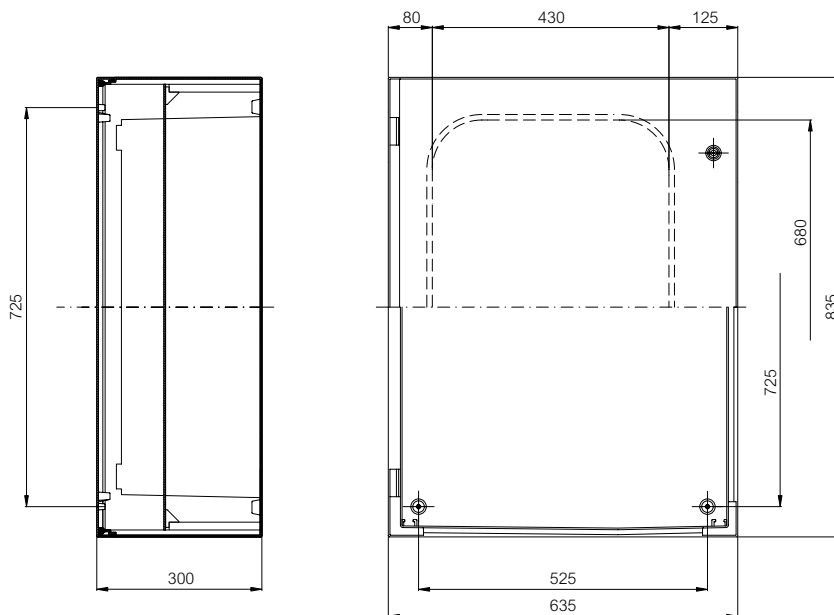

CAB 806030