

## Printed-circuit board connector - MCV 1,5/ 7-GF-3,5 P14 THR - 1780037

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Header, Nominal current: 8 A, Rated voltage (III/2): 160 V, Number of positions: 7, Pitch: 3.5 mm, Color: black, Contact surface: Tin, Mounting: SMD/THT/THR, User information and design recommendations for through hole reflow technology can be found under "Downloads"



The figure shows a 10-position version of the product

### Why buy this product

- ☒ Pitch: 3.5 and 3.81 mm
- ☒ Plug-in direction vertical to the PCB
- ☒ Low-profile THR headers with compact pitches
- ☒ Delivery form: box packaging, in bulk for small series
- ☒ Use in SMT reflow processes



### Key commercial data

|                                      |                                                                                                         |
|--------------------------------------|---------------------------------------------------------------------------------------------------------|
| Packing unit                         | 50 pc                                                                                                   |
| Minimum order quantity               | 50 pc                                                                                                   |
| GTIN                                 | <br>4 046356 532518 |
| Weight per Piece (excluding packing) | 1.38 g                                                                                                  |
| Custom tariff number                 | 85366990                                                                                                |
| Country of origin                    | Germany                                                                                                 |
| Note                                 | Made to Order (non-returnable)                                                                          |

### Technical data

#### Dimensions

|                |              |
|----------------|--------------|
| Length         | 6.9 mm       |
| Pitch          | 3.5 mm       |
| Dimension a    | 21 mm        |
| Pin dimensions | 0,8 x 0,8 mm |
| Hole diameter  | 1.4 mm       |

#### General

|                   |                    |
|-------------------|--------------------|
| Range of articles | MCV 1,5/...-GF-THR |
|-------------------|--------------------|

# Printed-circuit board connector - MCV 1,5/ 7-GF-3,5 P14 THR - 1780037

## Technical data

### General

|                                         |        |
|-----------------------------------------|--------|
| Insulating material group               | IIIa   |
| Rated surge voltage (III/3)             | 2.5 kV |
| Rated surge voltage (III/2)             | 2.5 kV |
| Rated surge voltage (II/2)              | 2.5 kV |
| Rated voltage (III/3)                   | 160 V  |
| Rated voltage (III/2)                   | 160 V  |
| Rated voltage (II/2)                    | 250 V  |
| Connection in acc. with standard        | EN-VDE |
| Nominal current I <sub>N</sub>          | 8 A    |
| Maximum load current                    | 8 A    |
| Insulating material                     | LCP    |
| Inflammability class according to UL 94 | V0     |
| Color                                   | black  |
| Number of positions                     | 7      |

## Classifications

### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 272607xx |
| eCl@ss 4.1 | 27260701 |
| eCl@ss 5.0 | 27260701 |
| eCl@ss 5.1 | 27260701 |
| eCl@ss 6.0 | 27260704 |
| eCl@ss 7.0 | 27440402 |
| eCl@ss 8.0 | 27440402 |

### ETIM

|          |          |
|----------|----------|
| ETIM 4.0 | EC002637 |
| ETIM 5.0 | EC002637 |

### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30211810 |
| UNSPSC 7.0901 | 39121409 |
| UNSPSC 11     | 39121409 |
| UNSPSC 12.01  | 39121409 |
| UNSPSC 13.2   | 39121409 |

## Approvals

### Approvals

## Printed-circuit board connector - MCV 1,5/ 7-GF-3,5 P14 THR - 1780037

### Approvals

#### Approvals

UL Recognized / cUL Recognized / VDE Gutachten mit Fertigungsüberwachung / EAC / cULus Recognized

#### Ex Approvals

#### Approvals submitted

#### Approval details

|                                                                                                 |       |       |
|-------------------------------------------------------------------------------------------------|-------|-------|
| UL Recognized  |       |       |
|                                                                                                 | B     | D     |
| Nominal current I <sub>N</sub>                                                                  | 8 A   | 8 A   |
| Nominal voltage U <sub>N</sub>                                                                  | 300 V | 300 V |

|                                                                                                    |       |       |
|----------------------------------------------------------------------------------------------------|-------|-------|
| cUL Recognized  |       |       |
|                                                                                                    | B     | D     |
| Nominal current I <sub>N</sub>                                                                     | 8 A   | 8 A   |
| Nominal voltage U <sub>N</sub>                                                                     | 300 V | 300 V |

|                                                                                                                             |       |
|-----------------------------------------------------------------------------------------------------------------------------|-------|
| VDE Gutachten mit Fertigungsüberwachung  |       |
| Nominal current I <sub>N</sub>                                                                                              | 8 A   |
| Nominal voltage U <sub>N</sub>                                                                                              | 160 V |

|     |
|-----|
| EAC |
|-----|

|                                                                                                      |
|------------------------------------------------------------------------------------------------------|
| cULus Recognized  |
|------------------------------------------------------------------------------------------------------|

### Accessories

#### Accessories

#### Coding element

# Printed-circuit board connector - MCV 1,5/ 7-GF-3,5 P14 THR - 1780037

## Accessories


Coding profile - CP-MSTB - 1734634

Coding profile, is inserted into the slot on the plug or inverted header, red insulating material




## Drawings


Drilling diagram

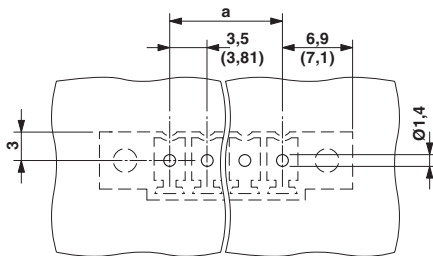

Dimensioned drawing

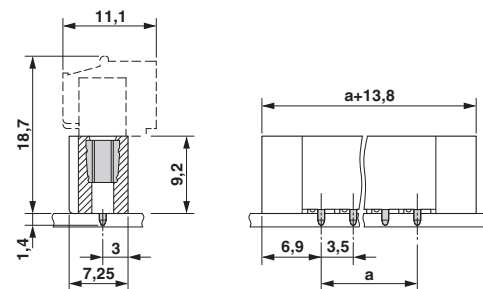

Diagram

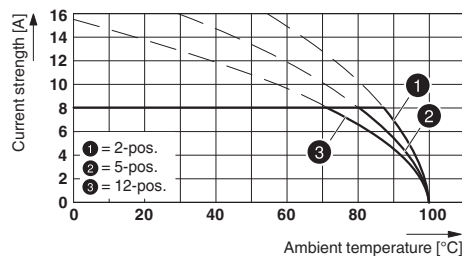

Type: MC 1,5/...-ST(F)-3,5 with MCV 1,5/...-G(F)-3,5 P... THR