

Moulded Boxes

ARCHITRAVE
SURFACE

K2151WHI 10
1 GANG
ARCHITRAVE BOX

K2152WHI 5
2 GANG
ARCHITRAVE BOX

Earth terminal fitted in base of boxes.

DIMENSIONS:
1 gang: 87 x 33 x 16mm
2 gang: 148 x 33 x 16mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

BS 5733: 2010

16mm
SURFACE

K2160WHI 10
FOR 1, 2 AND
3 GANG LOGIC PLUS™
PLATESWITCHES

K2161WHI 5
FOR 4 AND 6 GANG
LOGIC PLUS™
PLATESWITCHES

Earth terminal fitted in base of boxes. Knockouts provided in sides and bases.

DIMENSIONS:
1 gang: 87 x 87mm
2 gang: 87 x 148mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

BS 5733: 2010

30mm
SURFACE

K2140WHI 10
FOR 1 GANG
LOGIC PLUS™
POWER ACCESSORIES

K2142WHI 5
FOR 2 GANG
LOGIC PLUS™
POWER ACCESSORIES

Knockouts in base and sides for cable entry

K2142 and **K2153** are suitable for fitting over 1 gang and 2 gang BS 4662 flush steel boxes respectively

32mm
SURFACE

K2153WHI 5
FOR 3 GANG
LOGIC PLUS™
POWER ACCESSORIES

DIMENSIONS:
1 gang: 87 x 87mm
2 gang: 87 x 148mm
3 gang: 87 x 208mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm
3 gang: 180.9mm

BS 5733: 2010

32mm
SURFACE

2140WHI 10
FOR 1 GANG
POWER ACCESSORIES
SQUARE CORNERS

Knockouts are provided in base and sides for cable entry

DIMENSIONS:
1 gang: 87 x 87mm
2 gang: 87 x 148mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

BS 5733: 2010

44mm
SURFACE

2031WHI 10
FOR 1 GANG
POWER ACCESSORIES

Knockouts in base and sides for cable entry.

DIMENSIONS:
87 x 87mm

FIXING CENTRES:
60.3mm

BS 5733: 2010

DRY LINING
35mm
FLUSH

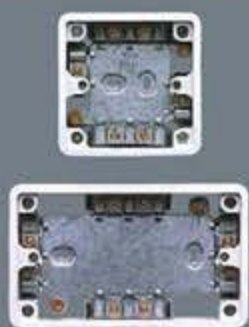
QFB/IG1 20
1 GANG WITH
INTUMESCENT GASKET

QFB/IG2 10
2 GANG WITH
INTUMESCENT GASKET

QFB/IG1 & QFB/IG2

Pre-fitted with intumescent gaskets to give fire protection, in accordance with BS 476 Pt.22: 1987. In a fire situation, a chemical reaction will occur with the intumescent material. The void behind the wiring device will be filled, providing protection against the passage of fire.

BS4662: 2006

MI CABLE BOXES
37mm
SURFACE

K2131WHI 5
1 GANG
10 CLAMPS

K2132WHI 5
2 GANG
12 CLAMPS

Clamps accept 20mm sealing pots.

DIMENSIONS:
1 gang: 92 x 92mm
2 gang: 92 x 152mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

BS 5733: 2010

DUAL BOX
38mm
SURFACE

K2025WHI 5
FOR MOUNTING
TWO X 1 GANG
LOGIC PLUS™
ACCESSORIES

This box has two slots in base with 60.3mm and 120.6mm fixing centres for fitting over BS 4226 flush boxes. Knockouts provided for cable entry.

Includes integral dividing fillet.

DIMENSIONS: 86 x 172 mm

BS 5733: 2010

40mm
SURFACE

K2031WHI 10
FOR 1 GANG
LOGIC PLUS™
POWER ACCESSORIES

K2172WHI 5
FOR 2 GANG
LOGIC PLUS™ 45 AMP
DP SWITCHES

Knockouts provided in sides and base.

K2172: Earth terminal fitted in base of box.

DIMENSIONS:
K2031: 87 x 87mm
K2172: 87 x 148mm

FIXING CENTRES:
K2031: 60.3mm
K2172: 120.6mm

BS 5733: 2010

FLANGE BOXES
45mm
FLUSH

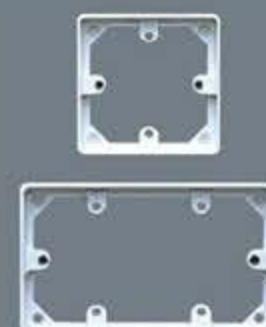
K2061WHI 5
1 GANG

K2062WHI 5
2 GANG

DIMENSIONS:
K2061: 88 x 88mm
K2062: 88 x 148mm

FIXING CENTRES:
K2061: 60.3mm
K2062: 120.6mm

BS 5733: 2010

Mounting
Frames For
Trunking

K2134WHI 10
1 GANG 20MM DEEP
FOR LOGIC PLUS™
ACCESSORIES

K2133WHI 10
2 GANG 20MM DEEP
FOR LOGIC PLUS™
ACCESSORIES

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

BS 5733: 2010