



Datasheet

NEWlink 25 mtr HDMI Male to HDMI Male Active Optical Cable (AOC)

Stock number: 2240982


EN

The NEWlink 25 metre HDMI male to HDMI male, Active Optical Cable which has a black TPE jacket with an outer diameter of 4.8mm. The connectors are metal and have gold flash covering to prevent corrosion.

Active Optical Cable (AOC) uses fibre optical technology to allow the transmission of HDMI signal up to 100 metres with no interference or degradation of signal or quality of image.

AOC still has some copper cores to carry power along the cable so no need for a PSU at the display end.

HDMI is possibly the most common display connection on the market which can be found on devices ranging from PC's, Bluray players, games consoles and more.

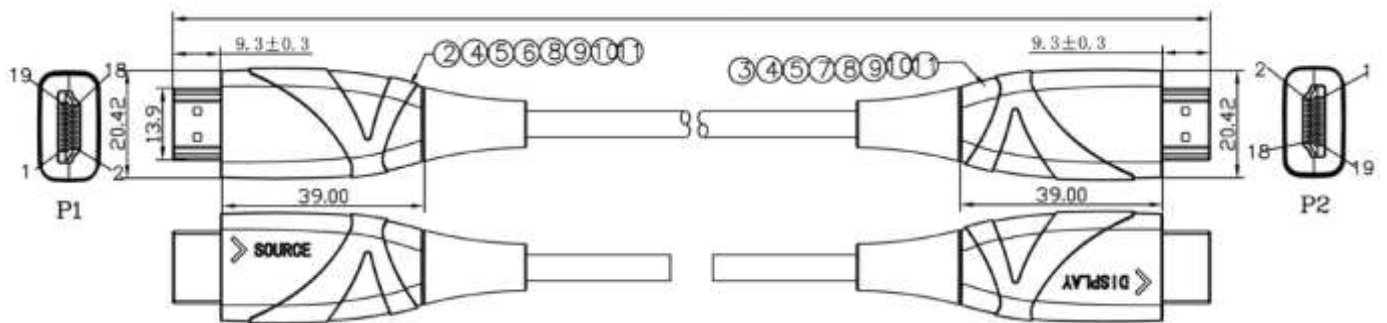

P1		P2	
LY	=====	LY	
ECE	=====	CEC	
Shell GND	=====	GND	Shell
HPD	=====	HPD	
LX	=====	LX	
VCC	=====	+5V	
UTY	=====	UTY	

12	Transparent yellow JUMP-4-core-For HDMI, DP modules
11	HDMI AOC-Screw-M1.6*5*0.2MM-Iron nickel plating
10	HDMI AOC-Buckle-Aluminum material
9	Brown high temperature tapeW=5MM 8mm*2pcs
8	HDMI AOC-Under shell-Zinc alloy-Gun colour-NDI-Marking
7	HDMI AOC-Upper shell-Zinc alloy-Gun colour-Neutral-Laser carving DISPLAY
6	HDMI AOC-Upper shell-Zinc alloy-Gun colour-Neutral-Laser carving SOURCE
5	PVC~60P~Black~Environmental requirements comply with NBP
4	HDMI M Transparent PVC Dust cover
3	HDMI Photoelectric conversion module (TX) DISPLAY
2	HDMI Photoelectric conversion module (RX) SOURCE
1	NO-UL-(30AWG(7/0.10TC)+EA)*2C+28AWG(19/0.08TC)*3C++24AWG(41/0.08TC)*2C+Optical fiber50/124.8u m*4C+AM-OD-4.8MM-jacket color:Black TPE-NO marking

RoHS / REACH / CE

