



Brand of NTN corporation

Technical data

USFCE207

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US207G2, FCE207

VISUAL (S)

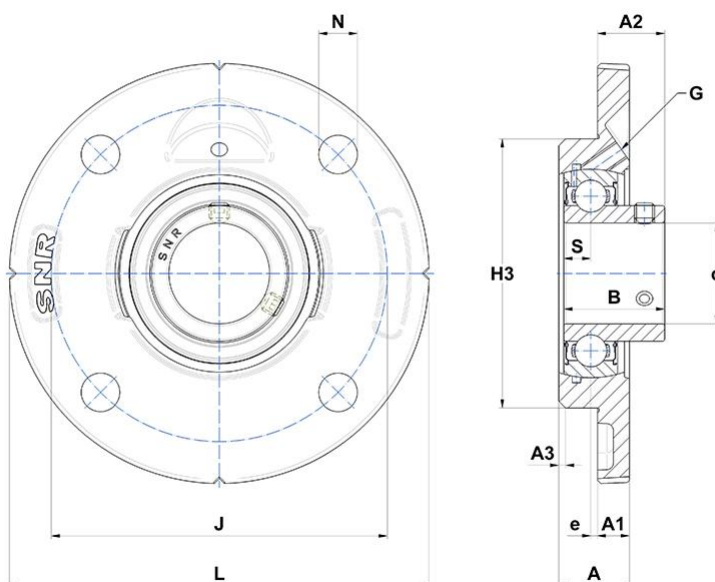

PRODUCT DEFINITION

Brand	SNR
A - Housing height	21 mm
A1 - Housing foot height / flange height	10 mm
A2 - Total height from mounting surface	22,5 mm
A3 - Centering depth / chamfer dimension	2 mm
B - Width of Inner Ring	32 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Shaft diameter	35 mm
e - Distance mounting surface to bearing center	-1 mm
G - Grease fitting	M6x1
H3 - Centering dia	90 mm
J - Mounting holes distance	110 mm
L - Housing width / diameter	135 mm
N - Mounting hole dimension	11,5 mm
S - Distance front side/bearing centre	8,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	1,19 kg
Recommended tightening torque for set screw	5.5 N-m

