

## Adapter plate - HC-B 10-ADP/2 DSUB 25 - 1775509


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



D-SUB adapter plate, for two D-SUB connectors, no. of positions 25, housing series HC-B 10...



### Key commercial data

|                                      |   |
|--------------------------------------|---|
| Packing unit                         | 2 pc  |
| Minimum order quantity               | 2 pc  |
| GTIN                                 | <br>4 017918 038106 |
| Weight per Piece (excluding packing) | 11.52 g   |
| Custom tariff number                 | 85472000  |
| Country of origin                    | Germany   |

### Technical data

#### Dimensions

|                                 |         |
|---------------------------------|---------|
| Length                          | 64.5 mm |
| Height                          | 34.5 mm |
| Hole diameter                   | 3.2 mm  |
| Drill hole distance, horizontal | 57 mm   |
| Drill hole distance, vertical   | 27 mm   |

#### General

|   |                    |
|---|--------------------|
| Note                                    | For housing HC-B10 |
| Material                                | PA                 |
| Inflammability class according to UL 94 | HB                 |
| Color                                   | gray               |
| Number of positions                     | 25                 |
| Type                                    | B10                |

# Adapter plate - HC-B 10-ADP/2 DSUB 25 - 1775509

## Classifications

### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27140816 |
| eCl@ss 4.1 | 27140816 |
| eCl@ss 5.0 | 27143424 |
| eCl@ss 5.1 | 27143424 |
| eCl@ss 6.0 | 27143424 |
| eCl@ss 7.0 | 27440209 |
| eCl@ss 8.0 | 27440201 |

### ETIM

|          |          |
|----------|----------|
| ETIM 3.0 | EC002309 |
| ETIM 4.0 | EC002309 |
| ETIM 5.0 | EC002309 |

### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30211808 |
| UNSPSC 7.0901 | 39121408 |
| UNSPSC 11     | 39121408 |
| UNSPSC 12.01  | 39121408 |
| UNSPSC 13.2   | 39121408 |

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

Approvals submitted

---


Approval details

|     |
|-----|
| EAC |
|-----|

## Drawings

## Adapter plate - HC-B 10-ADP/2 DSUB 25 - 1775509

Dimensioned drawing

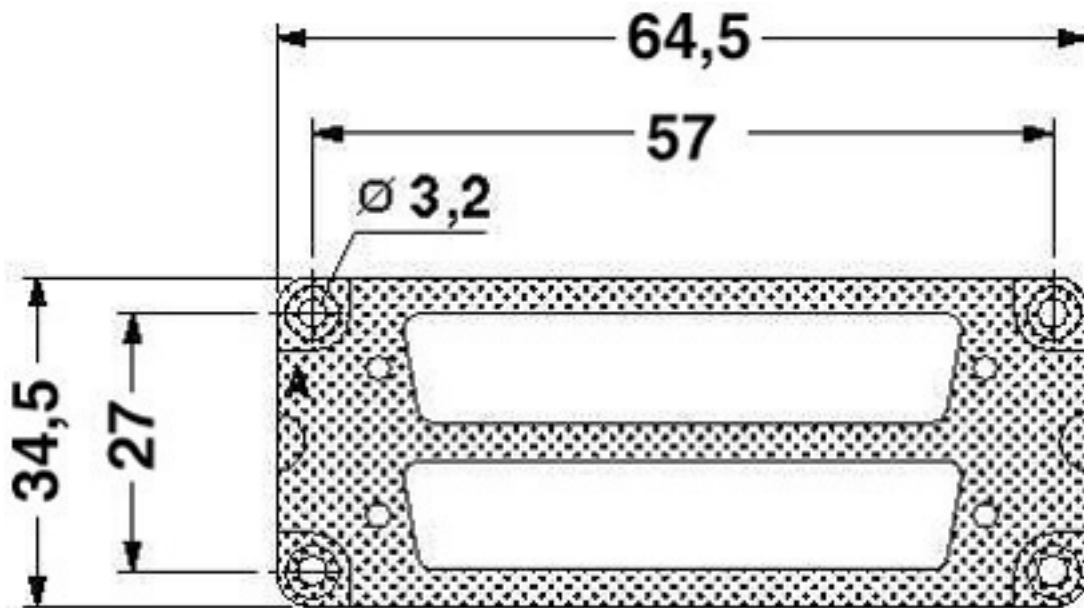

See assembly instruction