


NF E 74.303

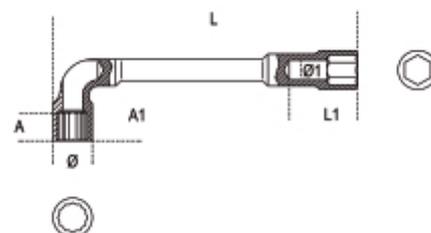

art.	mm	mm	mm	mm	mm	mm	mm	mm	mm	g
009320006	932 6X6	6x6	11,5	110	5,0	8,0	15,0	15,0	55	
009320007	932 7X7	7x7	12,5	116	6,0	9,0	18,0	15,0	60	
009320008	932 8X8	8x8	13,0	120	6,0	11,0	20,0	21,0	65	
009320009	932 9X9	9x9	14,0	125	7,0	11,0	20,0	21,0	75	
009320010	932 10X10	10x10	16,5	133	8,0	13,0	22,0	25,0	105	
009320011	932 11X11	11x11	17,5	143	8,5	14,0	23,0	25,0	125	
009320012	932 12X12	12x12	19,0	148	8,5	14,0	25,0	25,0	165	
009320013	932 13X13	13x13	19,5	154	9,5	16,0	28,0	34,0	175	
009320014	932 14X14	14x14	21,5	167	10,0	17,0	28,0	34,0	220	
009320015	932 15X15	15x15	22,5	182	10,0	17,0	29,0	40,0	235	
009320016	932 16X16	16x16	24,5	193	11,0	20,0	33,0	40,0	335	
009320017	932 17X17	17x17	26,0	198	12,0	20,0	34,0	44,0	340	
009320018	932 18X18	18x18	26,5	215	13,0	20,0	34,0	44,0	370	
009320019	932 19X19	19x19	29,0	220	14,0	22,0	35,0	48,0	435	
009320020	932 20X20	20x20	30,5	222	14,0	22,0	37,0	48,0	485	
009320021	932 21X21	21x21	30,5	236	16,0	25,0	39,0	48,0	575	
009320022	932 22X22	22x22	32,5	250	16,0	25,0	41,0	52,0	610	
009320023	932 23X23	23x23	33,5	256	17,0	26,0	44,0	52,0	705	
009320024	932 24X24	24x24	35,0	272	19,0	27,0	46,0	55,0	805	
009320025	932 25X25	25x25	36,5	282	19,0	27,0	47,0	55,0	895	
009320026	932 26X26	26x26	37,5	296	20,0	28,0	47,0	61,0	950	
009320027	932 27X27	27x27	39,0	296	21,0	28,0	50,0	61,0	1220	
009320028	932 28X28	28x28	39,0	314	22,0	28,0	51,0	61,0	1235	
009320030	932 30X30	30x30	42,5	348	23,0	31,0	51,0	70,0	1520	
009320032	932 32X32	32x32	45,5	364	24,0	32,0	51,0	70,0	1800	