


DEWALT

XR

WITH
FLEXVOLT
ADVANTAGE



TAKE ADVANTAGE OF MORE POWER

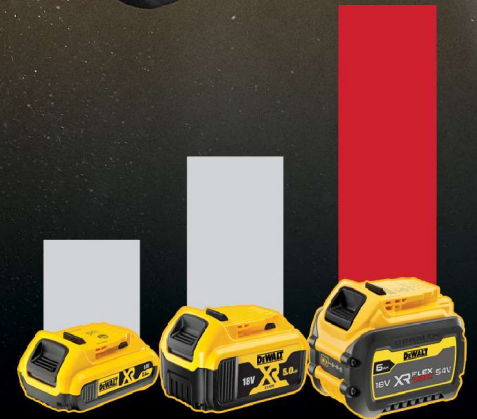

UP TO 50% MORE POWER*

DCS386 - 18V XR RECIPROCATING SAW WITH FLEXVOLT ADVANTAGE

The DCS386 delivers up to 50% more power when paired with a DCB546 XR FLEXVOLT 6Ah battery versus a DCB184 18V XR 5Ah battery. The DCS386 has been equipped with a crank type drive train for smoother, more efficient operation and reduced vibration, and delivers an impressive no-load speed of 3,000spm.

18V XR WITH **FLEXVOLT** ADVANTAGE

GUARANTEED TOUGH.®

18V XR RECIPROCATING SAW WITH FLEXVOLT ADVANTAGE

LED WORK LIGHT
Illuminates the cut line for increased visibility

CRANK TYPE DRIVETRAIN
Lower vibration



TOOL FREE BLADE CHANGE

BRUSHLESS MOTOR
For long runtime and tool life

FLEXVOLT ADVANTAGE TECHNOLOGY
TAKE ADVANTAGE OF MORE POWER



Up to 42% more power when used with an XR FLEXVOLT battery*



TAKE ADVANTAGE OF MORE POWER

*Using DCB546 6Ah XR FLEXVOLT battery vs. DCB184 5Ah 18V XR battery.

SPECIFICATIONS

STROKE LENGTH	29 mm
NO LOAD STROKE RATE	0 - 3000 spm
MAX. CUTTING CAPACITY	Wood 300 mm / Metal 130 mm
WEIGHT	3.5 kg

KIT OPTIONS

DCS386T1	1 X 6Ah Battery, TSTAK Kitbox
DCS386NT	Bare, TSTAK Kitbox
DCS386N	Bare Unit

DCD999T1 KIT INCLUDES

- (1) DCS386 Reciprocating Saw
- (1) DCB546 6Ah XR FLEXVOLT Battery
- (1) DCB116 XR 6A Charger
- (1) TSTAK VI Kitbox

RELATED ACCESSORIES



**Extreme Runtime
230mm Fast Wood
5 Pack**

DT99555-QZ



Copyright ©2020 DeWALT. The following are examples of trademarks for one or more DeWALT power tools and accessories: the yellow and black color scheme; the "D"-shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.

GUARANTEED TOUGH.®

www.DEWALT.com