
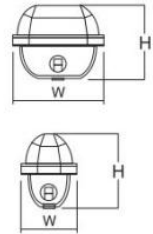


## Data Specification Sheet

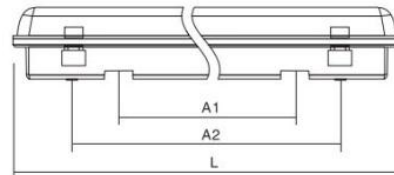

TR65HF 230V T8 IP65 Fluorescent Fittings

Description	IP65 T8 230V High Frequency Fluorescent Fitting							
Base Finish	Grey							
Product Code	712-6941	712-6957	712-6966	743-4845	712-6944	712-6950	712-6960	743-4854
Length (L)	655	1265	1565	1830	655	1265	1565	1830
Width (W)	95	95	95	95	145	145	145	145
Height (H)	100	100	100	100	110	110	110	110
Fixing Centre (A1)	420	900	1000	1000	420	900	1000	1000
A2	530	1010	1110	1110	530	1010	1110	1110
Wattage (W)	18	36	58	70	2x18	2x36	2x58	2x70
Circuit Watts	18.5	37	59	74	37	76	118	145
Number of Clips	6	10	12	12	6	10	12	12
Typical location	Indoor or Outdoor							
Lamp Supplied	No							
Voltage (V)	220 - 240V 50/60Hz							
Class	Class I. Must be Earthed							
IP	IP65							
Photometric Testing	Yes							
Instruction sheet	Yes							
Origin of manufacture	China							
Pack Included	Polycarbonate clips. Fixing brackets 20mm compression gland.							
Main materials:								
• Body	Polycarbonate							
• Diffuser	Polycarbonate							
• Gear Tray	Pressed Steel powder coated white							
• Clips	Polycarbonate (security type) Stainless Steel (Optional)							
• Gasket	Silicone Rubber							
Method of fix	Speed fix stainless steel brackets (Supplied)							
Lamp holder cap	G5 / Kang Rong							
Lamp type	T8							
Electrical Connections	L.E.N. Nylon Connector, Screw Terminals							
Control gear Operating Temperature	Knightsbridge H.F. Electronic ballast Optional 3 hour Maintained (EM) - 15°C to +30°C							
Dimmable	No							
Cold Store Version -20°C	No							
CE mark	Yes							
Quality Assurance System	Yes ISO 9001 QMS							
Batch coding details	Yes							
Certificate of Conformity	Yes							
Manufactured in accordance	EN60 598-2-1							
Guarantee Period	1 Year							