



Micro Timer II

TE Internal #: 2005372-3

6 Position Housing, Housing for Female Terminals, Wire-to-Wire, 4 mm [.16 in] Centerline, Sealable, Gray, Wire & Cable, Power, Micro Timer II

[View on TE.com >](#)

Connectors > Automotive Connectors > Automotive Housings > Timer Connector Housing



Number of Positions: 6

Connector & Housing Type: **Housing for Female Terminals**

Mating Tab Width: 1.6 mm [.06 in]

Connector System: **Wire-to-Wire**

Centerline (Pitch): 4 mm [.16 in]

[All Timer Connector Housing \(446\)](#)

Features

Product Type Features

Mixed & Hybrid Connector	No
Connector Shape	Rectangular
Connector & Housing Type	Housing for Female Terminals
Connector System	Wire-to-Wire
Sealable	Yes
Primary Locking Feature	Integrated in Housing
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	6
Number of Rows	2

Body Features

Cable Exit Angle	180°
------------------	------



Primary Product Color	Gray
Connector & Keying Code	B

Contact Features

Contact Size	1.6mm
Contact Type	Receptacle
Mating Tab Width	1.6 mm[.06 in]

Mechanical Attachment

Strain Relief	Without
Terminal Position Assurance	No
Mating Alignment Type	Keyed
Mating Alignment	With
Connector Mounting Type	Cable Mount (Free-Hanging)

Housing Features

Housing Material	PA 66 GF15
Centerline (Pitch)	4 mm[.16 in]

Dimensions

Row-to-Row Spacing	4 mm[.157 in]
Product Width	25.7 mm[1.01 in]
Product Length	28.3 mm[1.11 in]
Connector Height	24.15 mm[.95 in]

Operation/Application

Circuit Application	Power
---------------------	-------

Packaging Features

Packaging Quantity	300
Packaging Method	Bag

Other

Serviceable	No
Connector Position Assurance Capable	No

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
------------------------------	-----------




EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

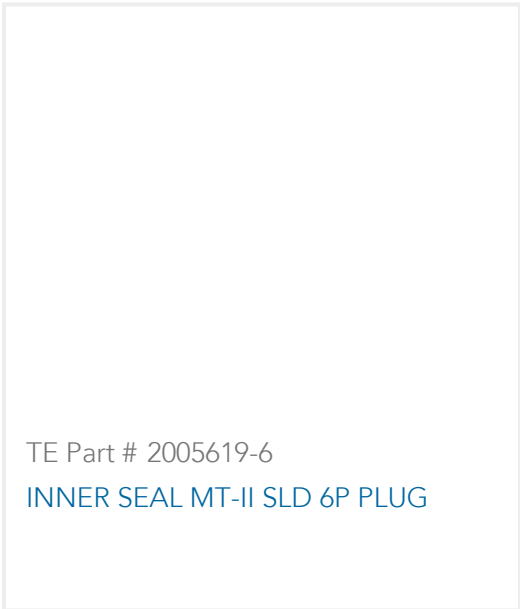


TE Part # 2005619-6
INNER SEAL MT-II SLD 6P PLUG



 
TE Part # CAT-T4827-T273
TIMER, RECEPTACLE AND TAB



TE Part # 2005373-3
MT-II SLD 6P PLUG HSG GRAY



TE Part # 2219369-2
COVER BLK FOR MT-II 6P PLUG




TE Part # 2-2188289-3
MTII 6P CAP ASSY-B


Also in the Series | Micro Timer II




Automotive Connector Caps & Covers
(1)

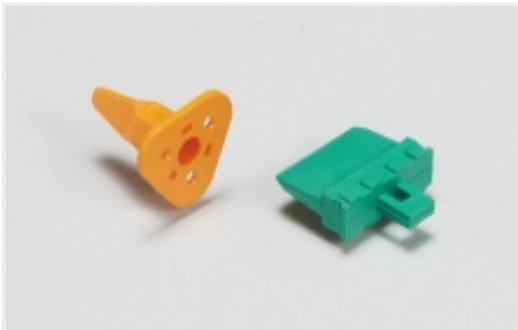

Automotive Connector Locks &
Position Assurance(1)

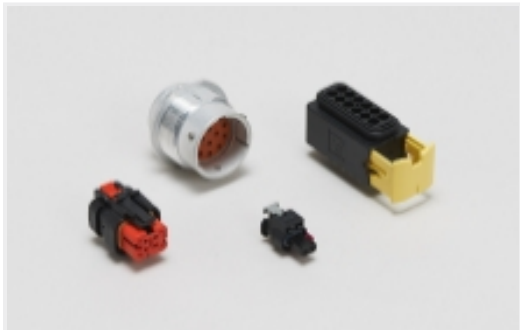

Automotive Housings(36)

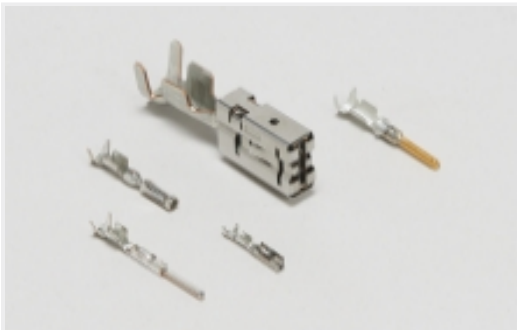

Automotive Terminals(34)



Connector Seals & Cavity Plugs(1)




Insertion & Extraction Tools(4)


Customers Also Bought



TE Part #2109006-3
060 REC(M) CONT

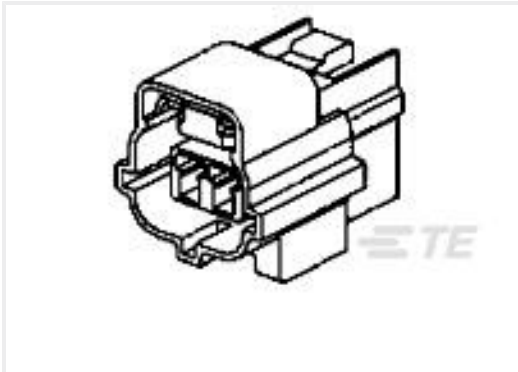

TE Part #368261-2
E-S MK-2(+) PLUG 2P ASSY

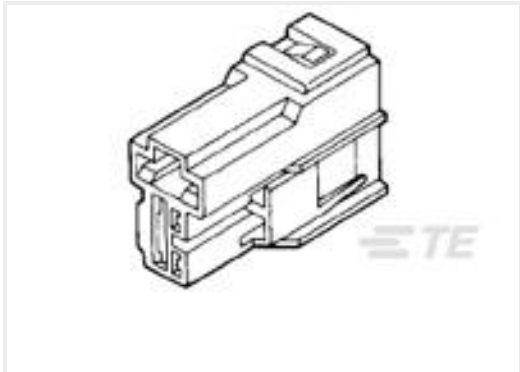

TE Part #172864-2
250 HSG. REC. 6mm 2P BLACK



TE Part #CAT-T4827-CH8172
Timer Connector Housing



TE Part #2005390-6
JPT SLD 3P PLUG ASSY-1S BLK



TE Part #936059-2
2.8MM SLD 2P PLUG ASSY



TE Part #6-2296315-2
ACU 52P PLUG ASSY(B6B10)



TE Part #CAT-M9194-CH8172
MULTILOCK, CONNECTOR HOUSING

Documents

Product Drawings
MT-II SLD 6P PLUG ASSY GRAY

English

CAD Files
3D PDF
3D
Customer View Model
ENG_CVM_CVM_2005372-3_C.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_2005372-3_C.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2005372-3_C.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Product Specification](#)

English