


- Lubricated for life sintered bearings
- Ball bearings
- Precision die-cast bearing housings
- 4.76mm or 6mm steel shaft, stainless steel and other diameters to special order
- Voltage range 24 to 415V AC
- Insulation grade to class B
- Resetting or non-resetting thermal protection
- Terminations 6.3mm male tabs or flying leads

SC9 Series Motors

This Single Phase AC Shaded Pole motor offers dependable and consistent performance. Typical applications are in Ovens, Cooker Hoods, Fan Heaters, Copying Machines, Vending Machines, Photographic Equipment, Domestic Appliances, Dental Equipment.

Suitable for similar applications requiring a low cost, long life, quiet running, small motor.

Dim "A"	Dim "B"	Type	Rating	Starting Torque GM/CMS	At 2000 RPM		WT. Kg
					Torque	Input Watts	
13	38	SC9 50	CONT.	74	83	15	0.45
			INT.	90	140	30	
19	44	SC9 75	CONT.	106	125	19	0.624
			INT.	140	245	38	
25	50	SC9 100	CONT.	136	168	24	0.794
			INT.	260	340	48	
32	57	SC9 125	CONT.	170	208	30	0.964
			INT.	323	400	60	
38	63	SC9 150	CONT.	205	240	35	1.14
			INT.	390	475	70	

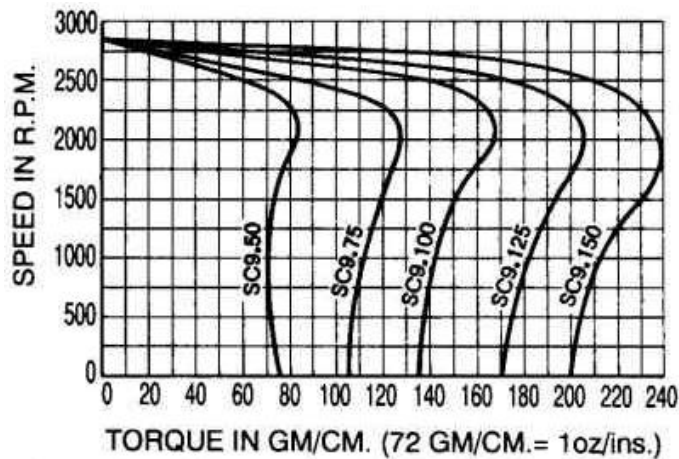

Torque/Speed Characteristics- Continuous rating

