


Universal Bevel Protractor Set

- set with 3 blades in different length

- stainless, hardened and fine ground
- scales matt chrome finish
- parallaxfree reading by vernier, with large magnifying lens
- with fine adjustment
- incl. angle stop (art. no.: 321276)

Option

- Wooden box: art. no.: 3299020

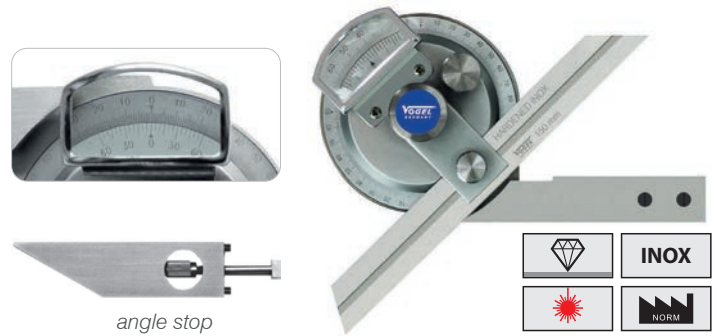

ART N°	length of blades mm		angle graduation °	
321220	150 / 200 / 300 mm	4 x 90°	1/12° = 5'	on request

Protractors (Skew Measurer)

- for standard mechanical engineering

- special steel, in chromed finish
- scale in matt chrome finish
- with adjustable blade, with fixing screw



ART N°	length of blades mm	arc-Ø mm	angle graduation °
320571	150	100	10 – 170°
320572	300	150	10 – 170°
320573	400	200	10 – 170°
320574	500	250	10 – 170°

Protractor

- with fixing screw
- with half round plate

- special steel, chromed
- scale matt chrome finish
- double graduation from 0° – 180° in opposite direction



ART N°	length of blades mm	arc-Ø mm		
322541	150	80	0 – 180	on request

Spare Parts for Electr. Digital Universal Protractors

- art.-no. 320100

ART N°	 spare blade
320101	150
320102	200
320103	300

ART N° 320101

ART N° 320102

ART N° 320103



ART N°	90° angled adjustment	
321275		60 x 50 / 15 x 4

ART N°	angle stop	
321276		70 / 40 x 18 x 4

