

Actuator

704.642.2

Distribution by
Rs-online



<https://rs-online.eao.com/p/704.642.2>

Your product:



704.642.2 Actuator

FRONT

Front dimension: Ø 29 mm

Front form: Round

MOUNTING

Design: Raised

Mounting type: Panel mounting

ELECTRICAL CHARACTERISTICS

Standards: The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

MECHANICAL CHARACTERISTIC

Weight: 0.009 kg

AMBIENT CONDITION

IP Protection: IP65 front side

Operating temperature: – 40 °C ... + 55 °C

Storage temperature: – 40 °C ... + 85 °C

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER


Short Description: Actuator, Ø 29 mm, Round

Housing colour: Grey


Housing material: Plastic

Product attributes: With series resistor for 110/125 V and filament lamp 60 V, 33 mA

Wiring diagrams:

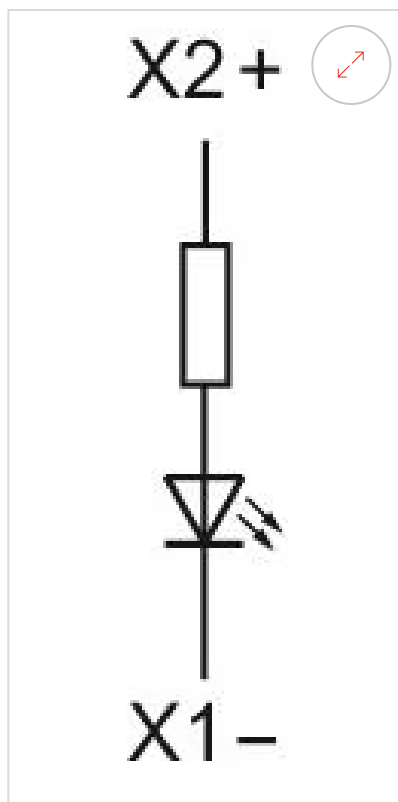

Mounting cut-outs:

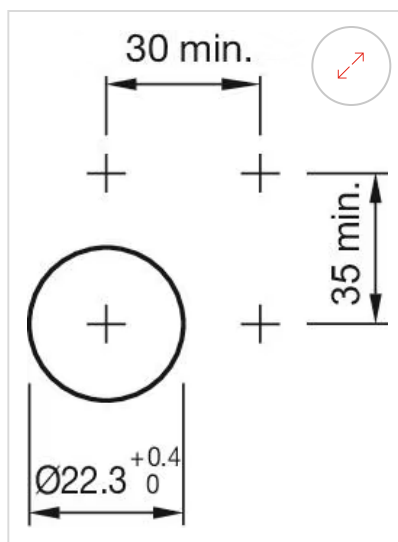

Dimension drawings:

