




LED FIL A60 B22d 12V-42V AC/DC 4W 310lm (29W) 827 Frosted

Article number: 145602

BAI LED Filament GLS A60 B22d Low voltage 12V-24V-28V-32V-42V AC/DC 4W 310lm (29W) 2700K Frosted 320° 60x105mm LED-lamp

LED filament lamps can be seen as the modern sustainable version of the old incandescent lamp. The so-called filaments replace the traditional filament, making the lamps many times more energy-efficient and last much longer. This low voltage series is especially suitable for rooms where one is not on the usual high-voltage network. Think of boats, cellars, garages and storage areas.

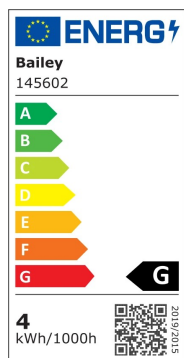

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL A60 B22d 12V-42V AC/DC 4W 310lm (29W) 827 Frosted
Brand	Bailey
Productseries	Low voltage LED filament
Producttype	A60 LV B22D 827 FR

ETIM specifications

Socket	B22d
Luminous flux [lm]	290 - 310
Nominal voltage [V]	12 - 42
Lamp power [W]	4 - 4
Colour temperature [K]	2700 - 2700
Diameter [mm]	60
Length [mm]	105
Dimmable	No
Lamp shape	Pear-shape
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Frosted
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC/DC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	310
Power factor	0.9
Lamp efficacy [lm/W]	77
Nominal current [mA]	170 - 170
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Other
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	4
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	G
With twilight switch	No
Material of light bulb	Glass

Complementary articles



146219

TOPO Little Transformer 12V AC 0-50W / LED 0-20W DIM



145683

TOPO Mini Transformer 12V AC 0-50W / LED 0-30W DIM