




## **PowerConnections**

### **ACP - USA/JAPANESE/CHINESE TO UK CONVERTER:**



**2 PIN PLUG**

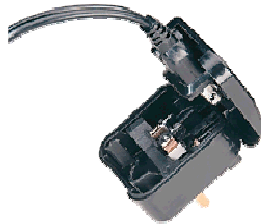

**2 PIN PLUG CLIPS INTO CONVERTER**



**COVER SNAPS SHUT & SECURED WITH SCREW**

The American standard plug adaptor is the latest converter plug from the Powerconnections range. This product also converts Japanese and Chinese plugs to BS1363.

Following the hugely successful Euroconverter plug, this new product offers a simple, safe and fast method of product conversion, without the need to strip cable or remove existing plugs.

The product converts both the non-polarised and polarised 2 pin plug. This can only be located the correct way round and, once firmly held in the guide strip, the lid is closed, making the connection and securing the plug. A simple screw retainer is then tightened. Please note: After fully assembling, a 'pull test' safety check is recommended (Not all Japanese plugs are suitable).

Extremely useful in alternative markets the converter plug can be fitted in a moment, on a production line, or at its final destination.

#### **TECHNICAL INFORMATION**

<i>Voltage</i>	240V 50Hz
<i>Current rating</i>	10 A
<i>Load</i>	2200W (max.)
<i>Fuse</i>	3,5, 10A BS1362
<i>Material</i>	PP CAD Free
<i>Weight</i>	45g (typical)

#### **STANDARDS**

The product is approved to BS5733, BS1363 plug/socket features and BS1362 fuse link. Approved by BSI. Product complies with current RoHS standards.

#### **COLOURS AVAILABLE**

Black / White