

Features

- Crocodile Clips
- Automotive clip
- Jaw open: 0.75" (19 mm) max
- Material: Steel
- Length: 2.84" (72.23 mm)
- Rating: 25 Amps

RS PRO Crocodile Clips,Zinc-Plated Steel Contact, 25A

RS Stock No.: 0205403



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Crocodile Clips



Product Description

- RS heavy duty alligator clips with screw and crimp terminations, are ideal for testing and battery connection purposes and other applications that require a heavy duty alligator clip.
- RS Electric Heavy Duty, General Purpose, Crocodile and Alligator Clips
- A concise offering of steel and copper alligator and crocodile clips from RS suitable for applications including grounding clips, test meters clips, battery terminal connection and many others that require a durable and hardwearing alligator or crocodile clip.

General Specifications

Material	Zinc-plated steel; Spring: steel
Product Name	Heavy Duty Clip
Type	Automotive clip Heavy Duty Clip for Battery and Test Work
Insulated	No
Connection Type	Can be attached by crimp or screw connection

Commented [波幸1]:

Electrical Specifications

Current rating	25A
----------------	-----

Mechanical Specifications

Jaw Opening ($\pm 10\%$)	0.75" (19 mm) max
Contact Material	Zinc-plated steel; Spring: steel
Insulation Material	No
Dimensions ($\pm 10\%$)	Overall length 2.84" (72.23 mm)


Approvals

Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

Spec Drawings Diameter

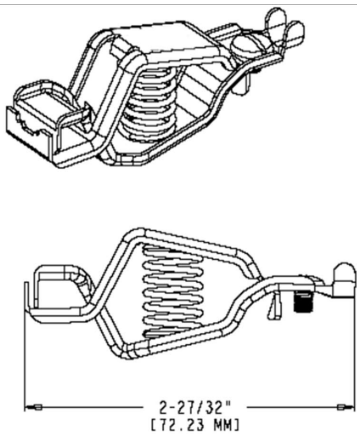

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION