


# Deep groove ball bearings, single row, unsealed



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
20	52	15	16,8	7,8	0,335	30000	19000	0,14	6304 *

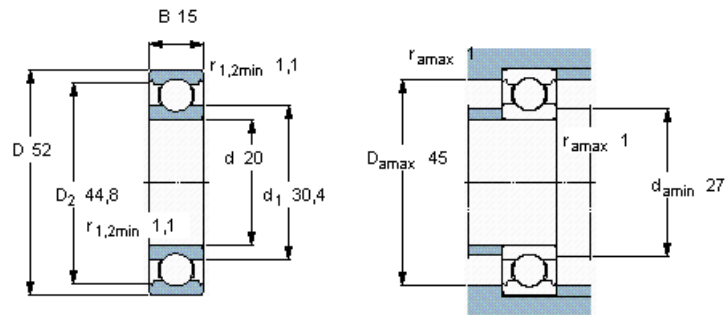

### Calculation factors

$k_r$  0,03  
 $f_0$  12