



Cut protection

KRYTECH 563

Low risk - ISO B



CUT PROTECTION
LEVEL B

EN388



4X43B

CATEGORY 2



ISO 13997:

6.5 N

DEXTERITY

EN ISO 21420:
5/5

Standard protection for intricate handling in dry and dirty environments

SPECIFIC ADVANTAGES



Durability

- Excellent life of duration thanks to an abrasion resistant coating
- Excellent resistance to greases



Skin protection

- Free of harmful substances: DMF Free



Guaranteed quality

- Silicone free to prevent traces, defects on metal sheet and glass prior to painting

INDUSTRIES

- Automotive/mechanical industry
- Construction Industry (Metalworkers/Locksmiths)
- Environment
- Paper industry

APPLICATIONS

- Handling sheet metal
- Waste collection and handling
- Handling cardboard and paper
- Mechanical maintenance
- Pressing metal, handling metal sheets




Cut protection

KRYTECH 563

Low risk - ISO B

LEGENDS

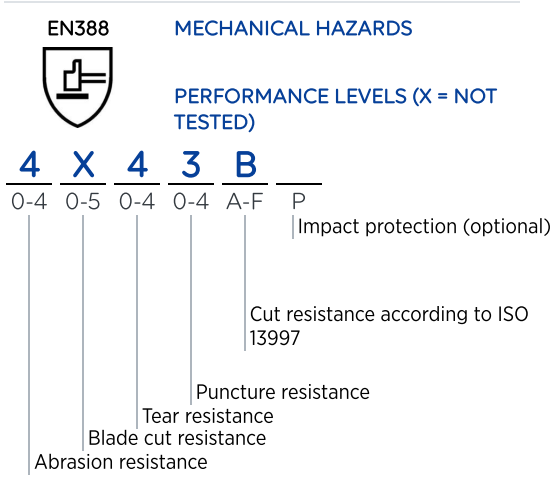

PRODUCT DETAILS

Interior finish	Seamless textile support from HDPE fibres
Gauge	13
Exterior finish	Ventilated back
Material	Nitrile
Cuff characteristic	Knitted Cuff
Colour.s	Black Grey
European sizes	7 8 9 10 11
Surface resistance according to EN1149-1 (Value in palm area at 25% relative humidity)	3.9E+10 Ω
Vertical resistance according to EN1149-2 (Value in palm area at 25% relative humidity)	7.0E+10 Ω

LOGISTIC DETAILS

Packaging	1 pair/bag 12 pairs/box
-----------	----------------------------

LEGISLATION

- This product is not classified hazardous according to the regulation (EC) n°1272/2008 of the European Parliament and of the Council.
- This product does not contain more than 0.1 % of substance of very high concern (SVHC) or any substance included in the annex XVII of the regulation n° 1907/2006 of the European Parliament and of the Council (REACH).
- UE type certificate or CE type examination certificate: 0075/014/162/08/18/1658 Update 01-20/02/2024
- Issued by the notified body nr: 0075 CTC - 4, rue Hermann Frenkel - 69367 Lyon Cedex 07- FRANCE