



Brand of NTN corporation

Technical data

USPFT206

Bearing units




Sheet metal housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US.206.G2, PFT206

VISUAL (S)

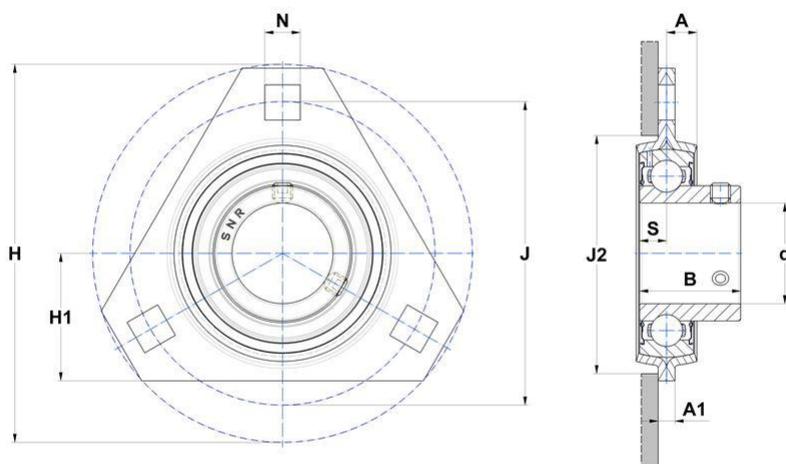

PRODUCT DEFINITION

Brand	SNR
A - Housing height	10,5 mm
A1 - Housing foot height / flange height	5 mm
A2 - Total height from mounting surface	24,5 mm
B - Width of Inner Ring	30 mm
d - Shaft diameter	30 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

e - Distance mounting surface to bearing center	2,5 mm
H - Housing length, width or diameter	112,7 mm
H1 - Distance housing side to centre of bearing insert	40,2 mm
J - Mounting holes distance	90,5 mm
N - Mounting hole dimension	10,5 mm
S - Distance front side/bearing centre	8 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	19500000 mN
C0 - Static load rating	11200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,48 kg
Recommended tightening torque for set screw	5.5 N-m

