


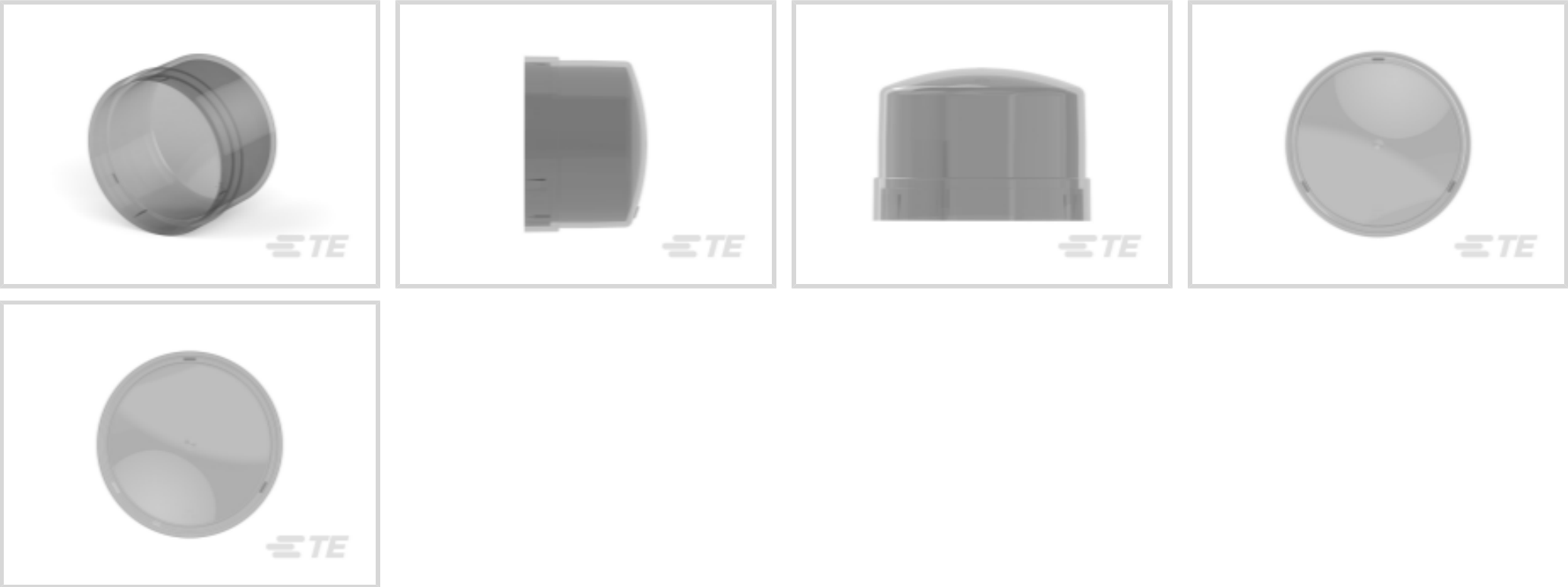

Connectors > Lighting Connectors > Street Lighting Controls > Street Lighting Accessories > Photo Control Cover



Lighting Product Type: **Cover**
Primary Product Color: **Gray**
Product Diameter: **81 mm [3.12 in]**
Lighting Connector Features Included: **Not Vented, Sleeve Compatible**

[All Photo Control Cover \(18\)](#)

Features

Product Type Features

Lighting Product Type	Cover
-----------------------	-------

Configuration Features

Lighting Connector Features Included	Not Vented, Sleeve Compatible
--------------------------------------	-------------------------------

Body Features

Primary Product Color	Gray
-----------------------	------

Dimensions

Product Diameter	81 mm[3.12 in]
------------------	----------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold



EU REACH Regulation (EC) No. 1907/2006

Current ECHA Candidate List: JAN 2025 (247)
Candidate List Declared Against: JUNE 2024 (241)
SVHC > Threshold:
UV-329 (.5% in Component Part)

Article Safe Usage Statements:
Wash thoroughly after handling. Do not handle until all safety precautions have been read and understood. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content

Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1-2336396-2
ASSEMBLY, LIGHT CONTROLLER BASE, W/VENT



TE Part # 2336396-2
ASSEMBLY, LIGHT CONTROLLER BASE, W/VENT



TE Part # 1-2213871-2
LIGHT CONTROLLER BASE ASSY, 81MM DIA,5POS



TE Part # 2213871-2
LIGHT CONTROLLER BASE ASSY, 81MM DIA,7POS


Also in the Series | LUMAWISE Endurance N



Street Lighting Accessories(18)




Street Lighting Base Assemblies(31)

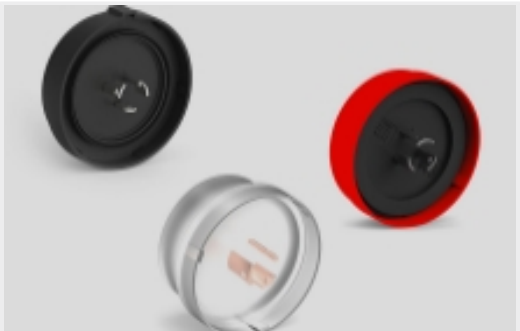

Street Lighting Open & Shorting Caps (3)



Street Lighting Power Management(6)

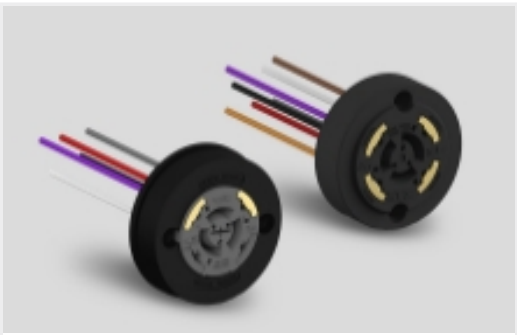

Street Lighting Receptacles(25)

Customers Also Bought



TE Part #1-2337216-3
RAIN-SKIRT, LUMAWISE
ENDURANCE S, DK GRY



TE Part #1-1546670-8
18P.437" DR BARRIER,W/BND SCRWB



TE Part #2328823-1
LUMAWISE S 80MM DIA DOME
SMOKE GRAY LOW



TE Part #6-1415036-1
PTML0524



TE Part #2213831-3
BASE ASSY, 80MM, SEALED




TE Part #2213831-2
BASE ASSY, 80MM, VENTED, SEALED



TE Part #1-1415526-1
PT78742



TE Part #1-2337216-1
RAIN-SKIRT, LUMAWISE
ENDURANCE S, BLACK

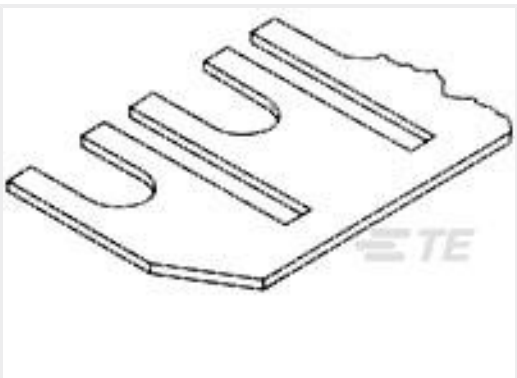

TE Part #5-1437644-4
J8-2=J8-XX JUMPER



TE Part #ANT-916-HETH
Antenna 1/4 Wave Coil 868MHz THM

Documents

Product Drawings

COVER, LIGHT CONTROLLER, 81MM DIA., 62MM

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2315539-1_B.2d_dxf.zip



English

Customer View Model
[ENG_CVM_CVM_2315539-1_B.3d_igs.zip](#)

English

Customer View Model
[ENG_CVM_CVM_2315539-1_B.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages
[LUMAWISE STREET LIGHT DIMMING AND CONTROL QUICK REFERENCE GUIDE](#)

English

[LUMAWISE ENDURANCE N CONTROL BASE, SLEEVE AND COVER](#)
[LUMAWISE ENDURANCE N CONTROL BASE, SLEEVE AND COVER](#)

English

Product Specifications
[Application Specification](#)

English

Agency Approvals
[UL](#)

English