

Features

- Panel mounting type
- Offer 5 poles
- Solder type termination

Female DIN
connector jack

RS PRO DIN Connectors

RS Stock No.: 0652725



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.


Product Description

- Enables a secure signal and current transmission
- Can be used in various applications to connect devices including, personal computers, audio and video to power, serial and data

Product range

Parameters	0652725
Number of Contacts	13
Gender	MALE
Mating Type	cable Mount
Termination Method	Solder
Body Orientation	Straight
Shielded/Unshielded	Shielded
DIN Number	DIN 45326
Housing Material	ABS
Contact Plating	NICKEL
Contact Material	Copper
Current Rating	1A
Voltage Rating	100V
Contact Resistance	<30 mΩ
Insulation Resistance	100 mΩ Min @ 500 V dc
Withstands Voltage	250 V ac
Dielectric Strength	500V AC/1 Minute
Rated impulse voltage	1000 V
Applicable Wires	AWG 22-26
Cross-sectional area	max. AWG 20
Minimum Operating Temperature	-20°C
Maximum Operating Temperature	85°C

Pollution degree	2
IP Rating	IP40
Cable outlet	2.5 - 6.0 mm
Mechanical operation	> 500 Mating cycles
Compliance/Certifications	UL94-HB

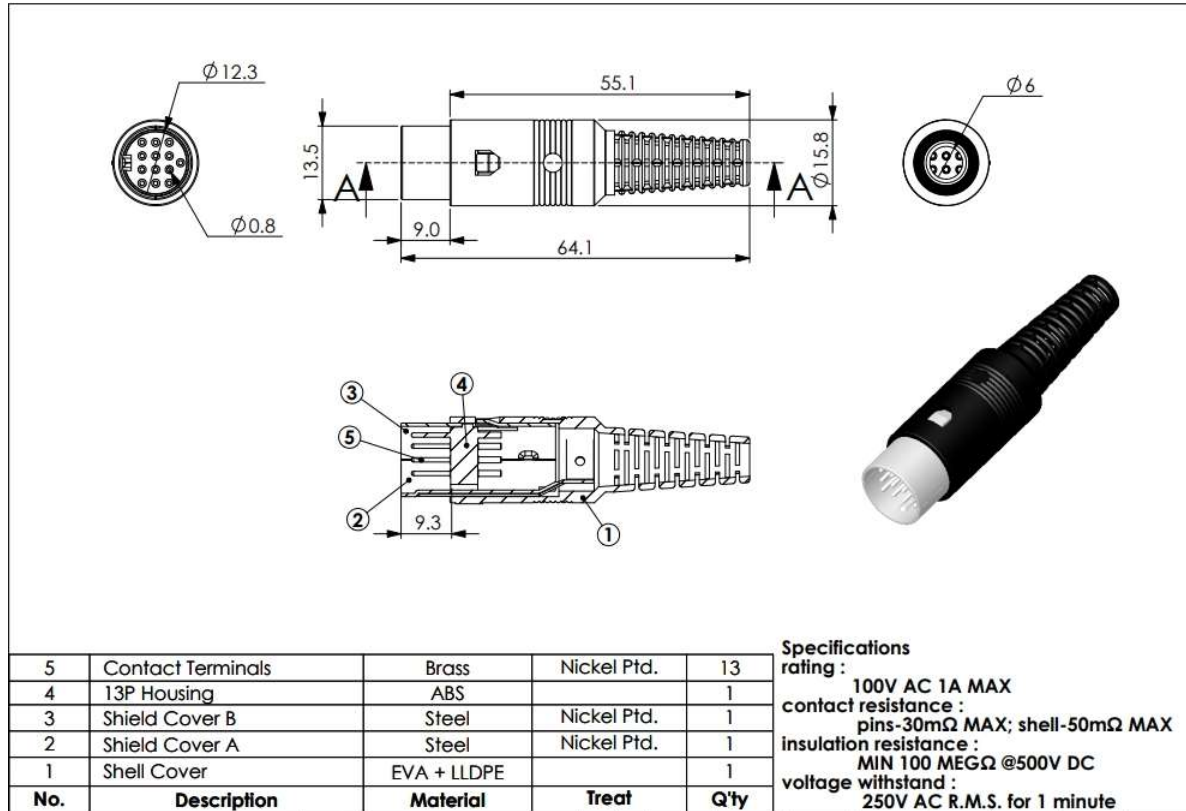

INCLUDES WITH PRODUCT: / STANDARD ACCESSORIES /
CONSTRUCTIONAL