
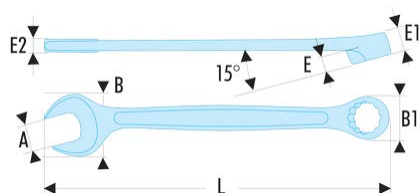


440.11SLS 440.SLS - Metric combination wrenches

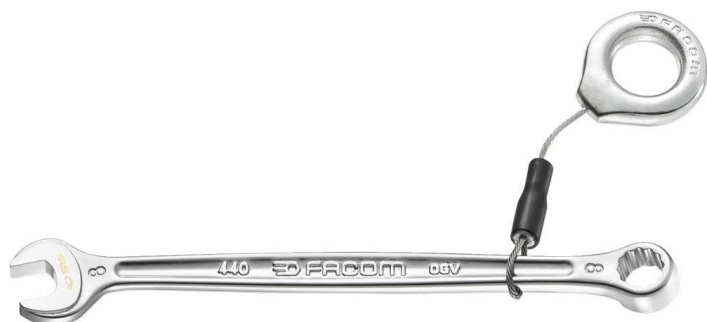

Description :

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The crimped "sliding" cable solution, selected and tested by FACOM, maintains user ergonomics (8 - 30 mm wrenches).
- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
 - Ring open end (size E) designed for better access to series or embedded screws.
 - OGV® profile with 12-point ring for powerful tightening while protecting the nut.
 - Ring head angled at 15°.
- Open end head:
 - Open end angled at 15°.
 - Open end head-handle geometry optimised for increased access.
- Metric sizes: 6 to 34 mm.
- Presentation: satin chrome finish.

A [mm]: 11

B [mm]: 24,5

B1 [mm]: 16,9

C1 [mm]: 8,1

E [mm]: 4,6

E1 [mm]: 8,1

E2 [mm]: 5,5

L [mm]: 155

[g]: 75
