


# push-in fitting NPQH-D-M5-Q6-P10

Part number: 578335

FESTO

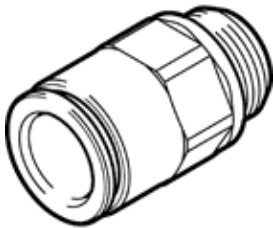

## Data sheet

Feature	Value
Size	Standard
Nominal size	2.5 mm
Type of seal on screw-in stud	Sealing ring
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 20 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	3 - High corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	0 ... 150 °C
Max. tightening torque	1.5 Nm
Product weight	11.2 g
Pneumatic connection, port 1	Male thread M5
Pneumatic connection, port 2	For tubing outside diameter 6 mm
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material of threaded seal	FPM
Material release ring	Nickel-plated brass
Material of tubing seal	FPM
Material of tube retaining claw	High alloy steel, non-corrosive