

# GRÄSSLIN

Tel: 01732 359888 Fax: 01732 354445

## SPECIFICATION SHEET




FEELING CH1



FEELING CH1

Sliding cover moved to reveal programming buttons

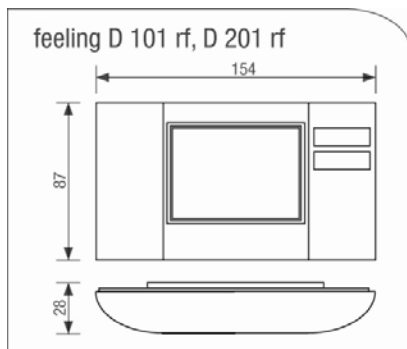

## Feeling digital programmable thermostat Hard-wired

### PRODUCT/ORDER CODE

FEELINGCH1                      single channel                      6 Amps

The Grasslin Feeling controller is a battery-powered programmable thermostat for 24 hour / 7 day control of space heating – suitable for a combination boiler, or for regulation of the space heating output from a system boiler. Allows setting of a temperature profile throughout the day, with individual day or day group programming. Temperatures can be set at half-hour increments in the range 5°C – 32°C

### Technical specification:

Surface mount centres	40mm; 60mm; 85mm
Supply voltage	3.0V DC (2 x AA alkaline)
Battery change reserve limit	10 minutes
Weight	200g
Connection	max. 1.5mm <sup>2</sup>
Switching capacity	6 (2)A @ 250V AC
Storage temperature	-20°C to +55°C
Timing accuracy	typ ± 1 sec. / day @ 20°C
Temperature control accuracy	0.5°C
Manual override	Yes
Control range	+5°C ..... +32°C
Display range	0°C ..... +50°C
Minimum programme increment	30 minutes
Daylight saving function	automatic
Display parameters	Day, date, time, set temperature, Ambient temperature, mode, Programme graphic