

## 44.17X19 | 44 - METRIC OPEN END WRENCHES




### Norm :


NF ISO 10102, NF ISO 3318, NF ISO 1711-1, NF ISO 691, ISO 10102, ISO 3318, ISO 1711-1, ISO 691, DIN ISO 1711-1, DIN ISO 691, DIN 3110

### Description :

- Open end wrenches = the open ends are slimmer than a standard combination wrench for better thickness accessibility. Examples: brake calipers, hydraulic hose locknuts.
- Heads hinged at 15°.
- Metric sizes: 3.2 to 42 mm.
- Presentation: satin chrome finish.

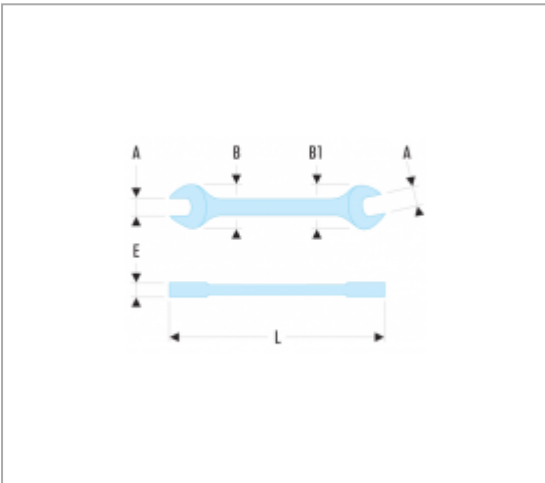

### Informations :

	44.17X19
A [mm]	17x19
B x B1 [mm]	39,0 x 42,0
E [mm]	7,3
L [mm]	220
[kg]	0.174