


Audio Cables

HIGHLY FLEXIBLE SPEAKER CABLES: **SFHP 215 – SFHP 225**



SFHP225

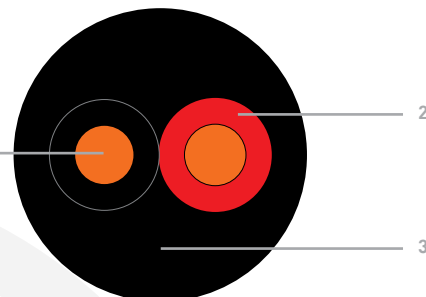

1. Composition of core: multi-strand bare copper
SFHP215: 182 x 0,10 mm
SFHP225: 310 x 0,10 mm
2. Conductor insulation: PVC
Color coding of conductors: red, black
3. Jacket: Black PVC

APPLICATIONS

- Wiring of all types of sound systems
- Connection of amplifiers and speakers
- Ideal for mobiles applications: on-stage performances ...

PRODUCT ADVANTAGES

- Oxygen-free copper for better sound quality and longer life span
- High flexibility thanks to 0,10 mm core conductors and ultra flexible PVC jacket
- Easy to wind
- Available in diameters of 1,50 mm² and 2,50 mm²
- Available in cords – ON AIR PRO range

ELECTRICAL CHARACTERISTICS

- Operating voltage: 300 V

MECHANICAL CHARACTERISTICS

- Operating temperature: -20°C - + 70°C
- Bend radius: Fixed station: 5 x outer diameter
Mobile station: 10 x outer diameter

SUITABLE PLUGS

- 3 pins XLR, Jacks, speakon

Part Nb	Nb of conductors	Section	Jacket	Outer diameter	Weight	Packaging
SFHP215	2	1.50 mm ²	Black PVC	6.20 mm	60 kg / km	100 m and 500 m
SFHP225	2	2.50 mm ²	Black PVC	7.40 mm	87 kg / km	100 m and 500 m