


# E75228



## Push-in L-fitting for pneumatic connections

AirBox push-in L-connect 10pcs

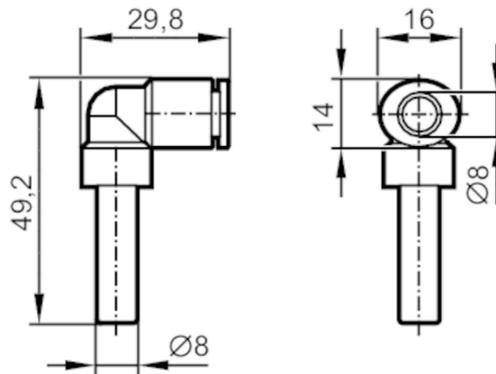

### Application

Media compressed air according to ISO 8573-1: 2001

### Operating conditions

Operating pressure [bar] 10; (min. -0,95)

Ambient temperature [°C] -20...80

### Mechanical data

Weight [g] 69.5

Materials housing: nickel-plated brass / PA66; release ring: polyoxymethylene;  
Tooth lock washer: stainless steel; form ring: NBR

Tube fittings 8 mm

Sleeve diameter [mm] 8

### Remarks

Pack quantity 10 pcs.