

# RGBW LED Flexi Strip



## Key Features:

- Even LED RGB colour and white lighting
- Supplied with 3M tape as standard
- 60 LEDs per mtr (RGB and white in single chip)
- IP65 rating
- 50,000 hours working life
- Multiple applications for commercial and residential environments
- Precise LED binning enables 100% consistent colour temperature from batch to batch
- Available in three white colour temperature


## RGBW 60 LEDS SPECIFICATION

Part Code	F12-RGBWW-24-60-65-FP	F12-RGBNW-24-60-65-FP	F12-RGBCW-24-60-65-FP
Voltage	24VDC	24VDC	24VDC
Power Consumption	19.2W per mtr	19.2W per mtr	19.2W per mtr
LED Qty	60 per mtr	60 per mtr	60 per mtr
LED Pitch	16.7mm	16.7mm	16.7mm
Lumen Output	910lm/M	910lm/M	910lm/M
CRI	>80Ra	>80Ra	>80Ra
Cut Points	100mm	100mm	100mm
CCT Colour Tone	3000K + RGB	4000K + RGB	6000K + RGB
IP	IP65	IP65	IP65
Back Adhesive	3M adhesive tape	3M adhesive tape	3M adhesive tape
Working Temperature	-20°C - +45°C	-20°C - +45°C	-20°C - +45°C
Humidity	40% - 70% RH	40% - 70% RH	40% - 70% RH
Dimensions	5000 x 12 x 2.1mm	5000 x 12 x 2.1mm	5000 x 12 x 2.1mm



## Mechanicals

### RGBW 60 LEDs

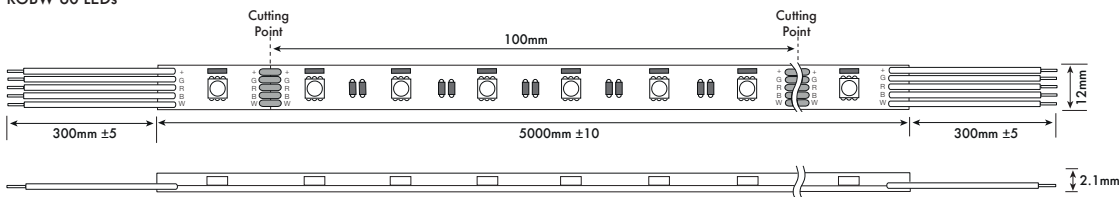

PowerLed (UK) Ltd  
Orion House  
Calleva Park  
Aldermaston  
Berkshire  
RG7 8SN

Contact:  
Tel: 0118 9703856  
enquiries@powerled.uk.com  
www.powerled.uk.com

