


# Literature holder FLEXIBOXX 6 A4 portrait

|                |               |                        |               |
|----------------|---------------|------------------------|---------------|
| Article number | 1709760400    | Sales unit quantity    | 1 Set         |
| Colour         | Transparent   | Sales unit EAN         | 7318089760405 |
| Packaging unit | 1 set         | Packing weight (gross) | 1881.65 G     |
| Base EAN       | 7318089760405 | Country of origin      | DE            |

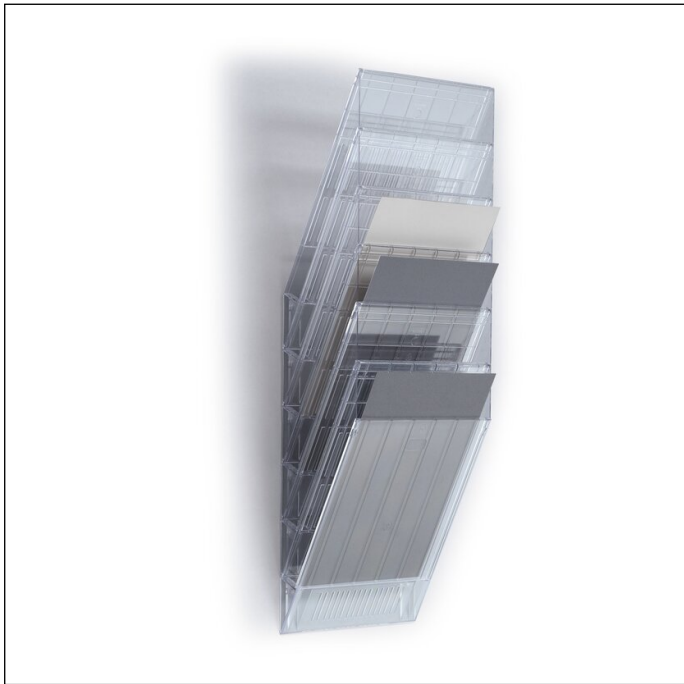

## Product description

- Wall-mounted literature holder with 6 compartments for information materials in A4 portrait format
- Filling capacity: 23 mm
- Extendable up to a load capacity of approx. 6 kg
- Ideal for information materials at reception desks, in showrooms, in waiting areas and at trade fairs

## Product features

|                                         |          |
|-----------------------------------------|----------|
| Outer width (mm)                        | 240      |
| Outer height (mm)                       | 690      |
| Outer depth / length                    | 135 mm   |
| Filling quantity / Filling quantity for | 24 mm    |
| Format / Format for                     | A4       |
| Orientation Format                      | Portrait |
| Brand                                   | DURABLE  |
| Inner width (mm)                        | 240      |
| Inner height (mm)                       | 690      |

1709760400\_PDS\_DURABLE\_en\_GB.pdf | 2026-07-19 05:27

1/2

# Literature holder FLEXIBOXX 6 A4 portrait

|                               |              |
|-------------------------------|--------------|
| Inner depth (mm)              | 24           |
| Number of Sections            | 6            |
| Opening for documents         | Top          |
| Extendable                    | Yes          |
| Recessed slot for easy access | No           |
| Max. load capacity            | Approx. 6 kg |
| Country of Origin             | Germany      |
| Base / mount type             | Wall mount   |