


# Bases for PROLINE® Sloped Top OI Enclosure System


Bulletin  
**VARIOUS**

## PROLINE Wall-Mount Kit

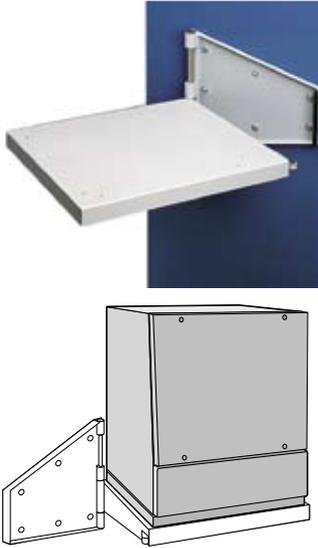


Hinged platform for a PROLINE sloped top enclosure pivots 90 degrees from wall bracket, thus allowing complete access to rear of the sloped top enclosure. The kit can be installed to pivot left or right, and locks securely in position against a wall. Pivot pin is removable. Platform can support equipment weighing up to 300 pounds and includes holes to mount 600mm wide sloped tops in two positions. RAL 7035 textured light gray polyester powder paint finish. Includes top unit to frame joining kit, catalog number PJSTF6, to provide a watertight and dusttight seal to the sloped top.

Catalog Number	A x B x C mm (in.)	Description	Bulletin Number
PWMK66	51 x 610 x 683 (2.0 x 24.0 x 26.88)	Steel	P9

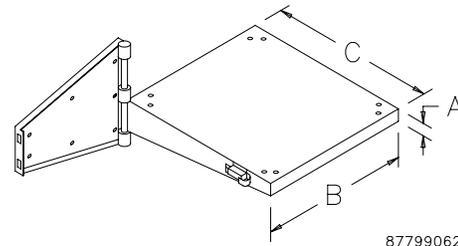


87799062

## Bases for PROLINE Sloped Top

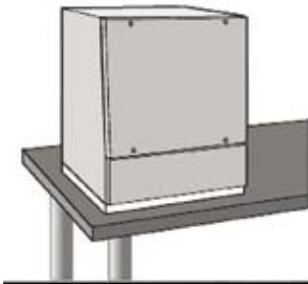


Closes off open bottom of sloped top enclosures that are table-top mounted or suspended from overhead. Base is 14 gauge steel and has a ground stud provided. Foam-in-place gasket assures a watertight and dusttight seal. Steel bases are finished with RAL 7035 textured light gray polyester powder paint. A top support bracket can be installed inside a 600mm wide base for reinforcement when COMPACT® pendant arm Series 4 System 50, 60, or 80 is attached from below.

0mm Base						
Catalog Number	Description	D (mm)	D (in.)	W (mm)	W (in.)	Bulletin Number
PBS66	Steel	542	21.34	608	23.94	P9, P20
PBS66SS	Stainless Steel	542	21.34	608	23.94	P9S, P20S
PBS86	Steel	542	21.34	808	31.81	P9, P20
PBS126	Steel	542	21.34	1208	47.56	P9, P20

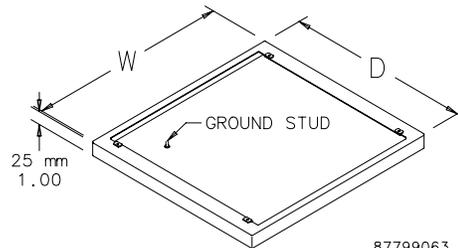

87799063

100mm Base						
Catalog Number	Description	D (mm)	D (in.)	W (mm)	W (in.)	Bulletin Number
PB166	Steel	559	22.01	599	23.58	P9, P20
PB166SS	Stainless Steel	559	22.01	599	23.58	P9S, P20S
PB186	Steel	759	29.88	599	23.58	P9, P20
PB186SS	Stainless Steel	759	29.88	599	23.58	P9S, P20S

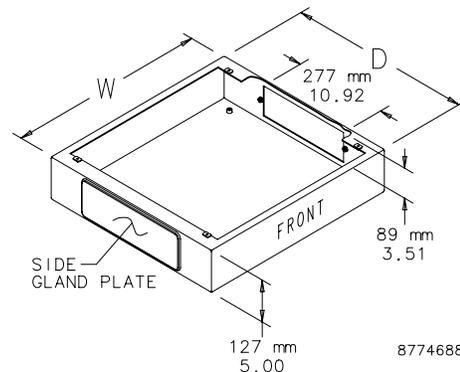

87746889