

Go to Step Search Screen


735410 -- 1 of 1 products

Terminals and Splices
ELECTRO-TAP Cable Connector/Splice

General **INFO**

Sales **INFO**

Customer Drawings **INFO**

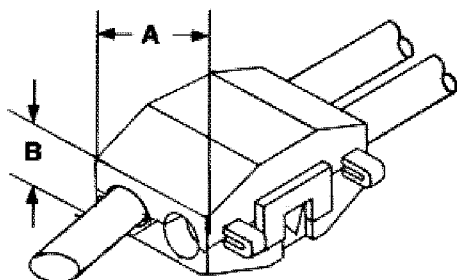

Line art represents typical product only.

Searchable Features:

Wire Range	0.50-0.75 mm ² AWG [mm]
Tap Wire Range	0.50 - 0.75 mm ²

Other Properties:

Dim. A	.492 [12.50] in. [mm]
Dim. B	.276 [7.00] in. [mm]
Insulation Diameter	4.0mm Max. in. [mm]
Housing Color	Red
Housing Material	Nylon
Contact Material	Brass
Contact Plating	Tin
Packaging Quantity	100