

ELARA

Elara is a Linear lamp, for lighting up surfaces in CNC-machines and other production machines. The LED's enables a long service life and low temperature impact, delivered with an L-bracket for mounting on walls or ceiling. An M12 male connector is fitted in the end piece for easy connection to 24V AC/DC.

Features


- LED service life >60000h
- 14W LED power
- Mounting bracket included
- Safe power supply to 24V AC/DC via M12 connector

Applications

- Machine shops
- Production industry
- Automated production lines

Benefits

- Low Power consumption
- Easy to install and adjust
- Minimal heat radiation

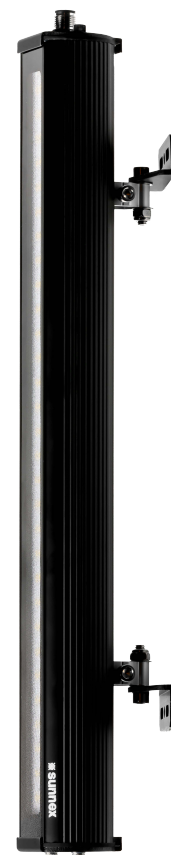




Technical specifications



Supply voltage	24VAC/DC, 4-pin M12 male connector A-coded
Power consumption	14W
Length	420mm
Mounting width bracket	20-430mm
Colour	Black
Colour temperature	4500K
IP rating	IP68
Protection class	III
Light output	1600Lm
Colour rendering index	>80
Weight	0,5kg
Life span	>60000h

Model	Connection	Version	Part. no
ELARA	24V AC/DC	14W, M12 Male connector	31300

 Accessory





4-Pin Female M12 connector
31301

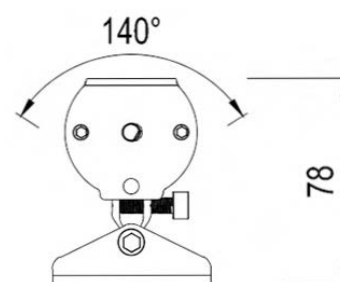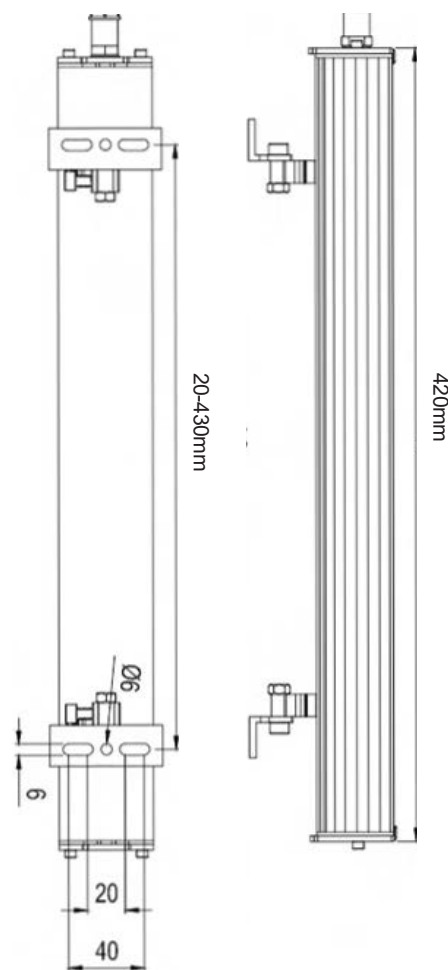

Male M12

Female M12

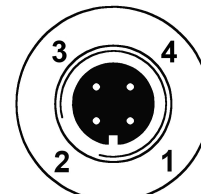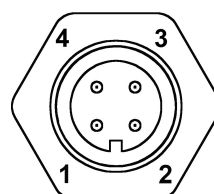

Active pins 1 and 3