


### Drawing of Component

Unit: mm Unless otherwise specified, tolerance:  $\pm 0.5$  mm

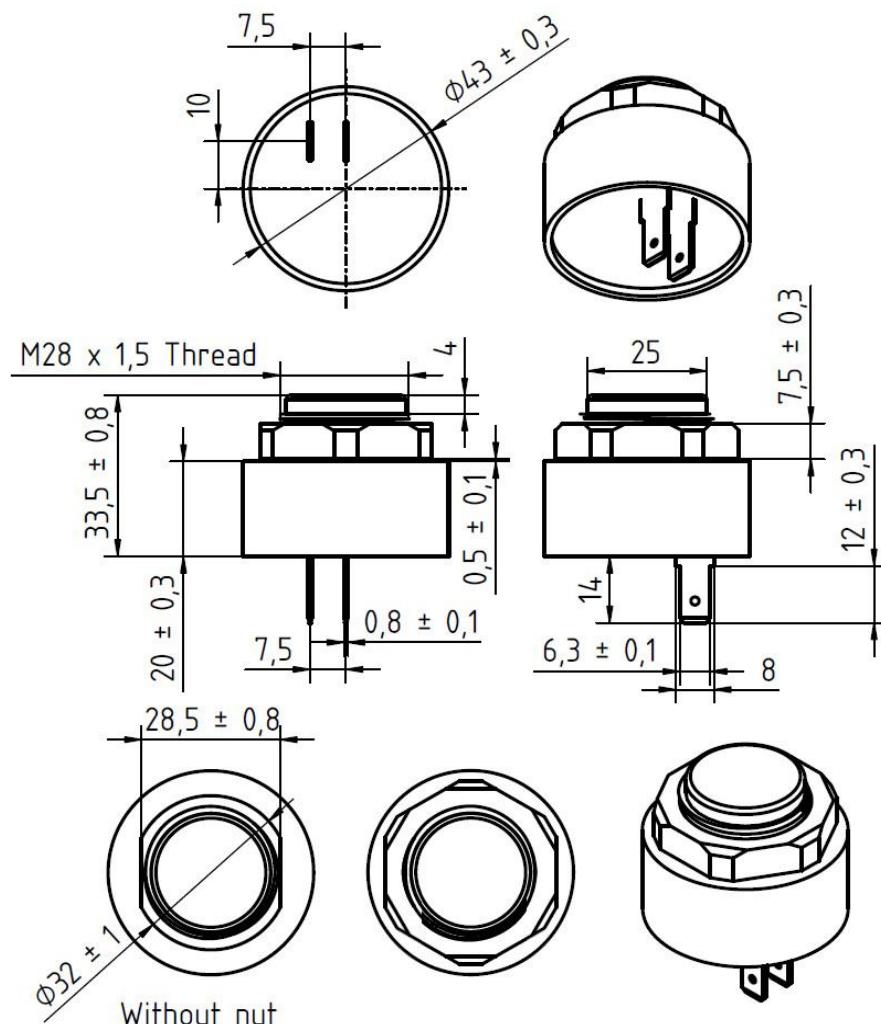

B/C28 BLACK

**Dimension**  
 $\phi 43 \times 33.5$  mm

**Operating Voltage**  
5-28 VDC

**Tone**  
Continuous Tone

**IP Rating**  
IP65

**Rated Voltage**  
12 VDC

**Sound Pressure Level**  
 $85 \pm 3$  dB(A) at 1 m

**Operating Temperature**  
-20 to +75 °C

**Oscillator Frequency**  
 $2900 \pm 500$  Hz