


Socket strip 4-fold with USB-C (Power Delivery) charger (type G)

Item-no.: 0201x06n5230b-1 (1,5 m cord)

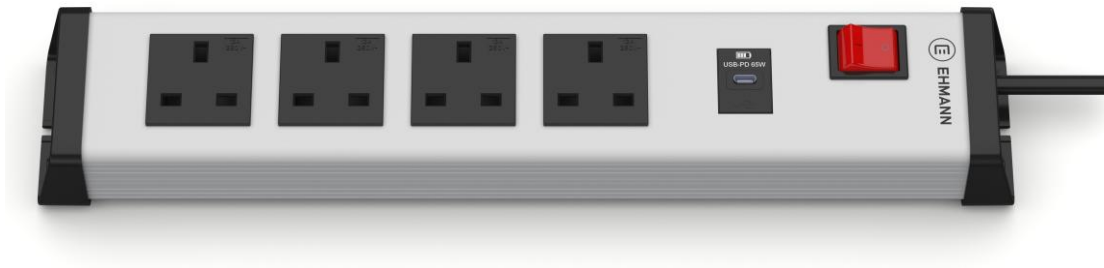

Robust plastic, grey

1x USB-C Port 65W with output voltage regulation

4 x Built-in sockets (90° rotated), quadrangular


Expanded contact protection by using a shutter

Enables fast charging through Power Delivery (PD)

Particularly suitable for mobile phones and tablets from Samsung, Apple, Huawei, HTC, LG, Sony, and more


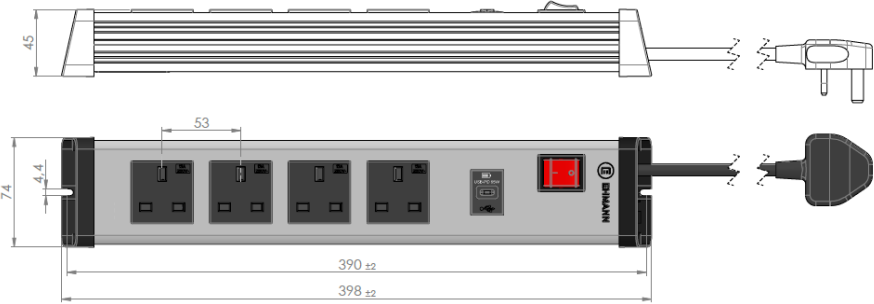
1,5 m power cord and angle plug, for flexible positioning

End caps with mounting possibility

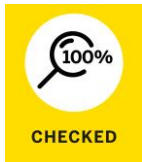

Socket strip 4-fold with USB-C (Power Delivery) charger (type G)

Technical data

3.600 W Power	250 V~ / 50 Hz Rated voltage	16 A Rated current
Power cord: H05VV-F 3G 1,5 mm ² - 1,5m length Plug: BP1 British Standard Type G, BS 1363/A, angled Sockets: Type G USB-C: 1-fold Charger Charging power: 65W max. 5V/3A for 15W 9V/3A for 27W 12V/3A for 36W 15V/3A for 45W 20V/3,25A for 65W Compatible: Apple, Android, Google, and more Safety class: IP20		
 <p>(similar illustration)</p>		
Item-no. 0201x06n5230b-1 (1,5 m cord)	EAN 4012096013501	PU 10 398 x 74 x 45 mm Dimensions (L x B x H) 390 mm Fixing dimensions (X)