


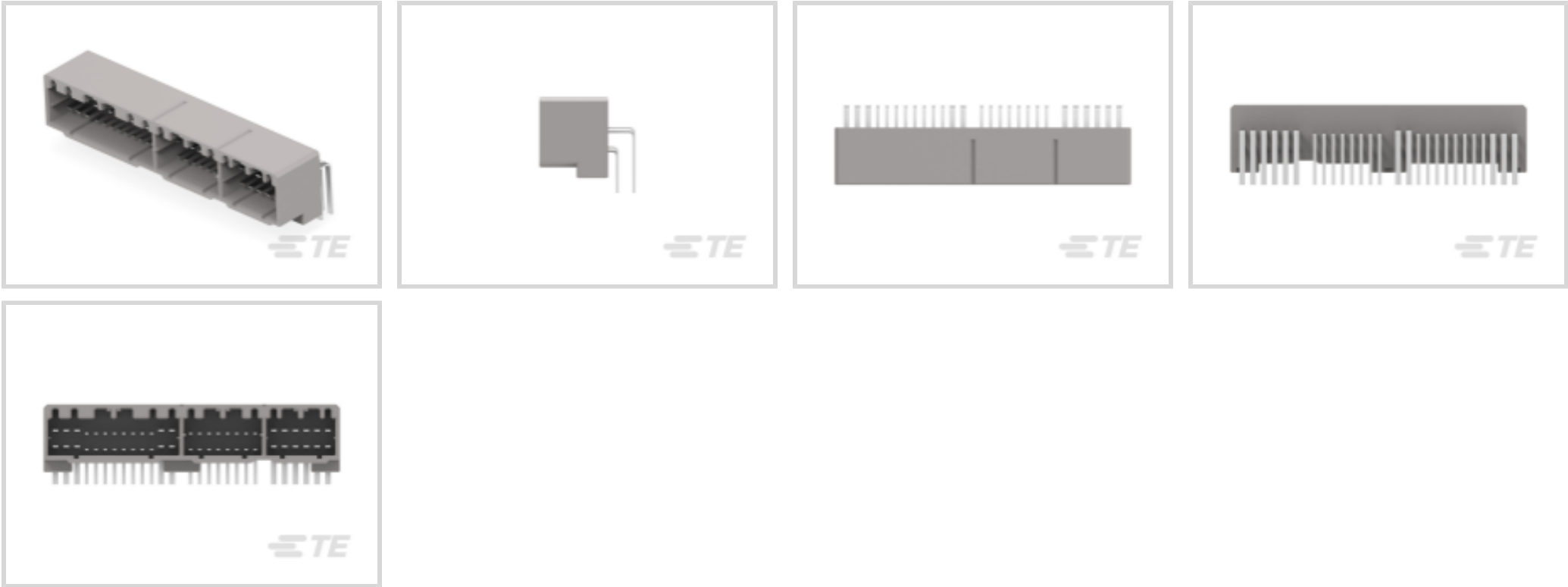

All High Pin Count Header (45)

Product Compliance

For compliance documentation, visit the product page on TE.com>


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Wave solder capable to 240°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

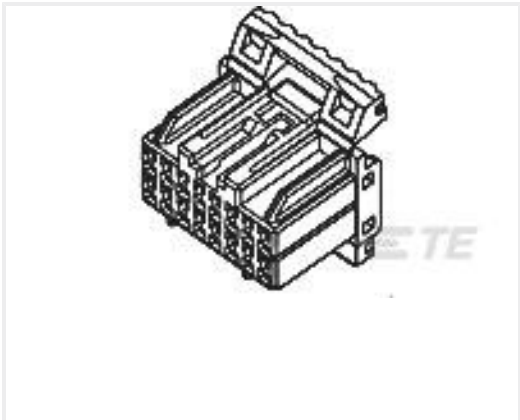


TE Part # 917635-8
040/070 HYBRID PLUG HSG 12P



TE Part # CAT-M9194-CH8172
MULTILOCK, CONNECTOR HOUSING


Customers Also Bought

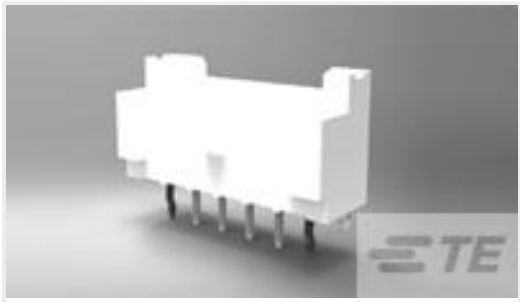


TE Part #2132415-2
EP2.5 Shrouded HDR ASSY 2P VERT w /o boss



TE Part #1SNK705012R0000
ZK2.5-4P

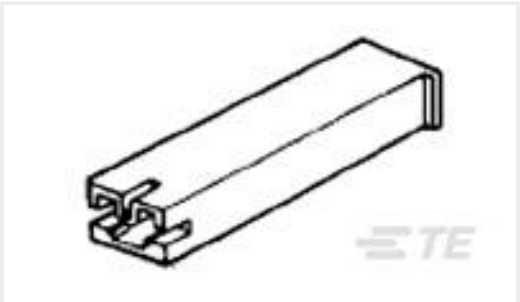

TE Part #172074-1
187 HSG. PLMKII REC. NAT

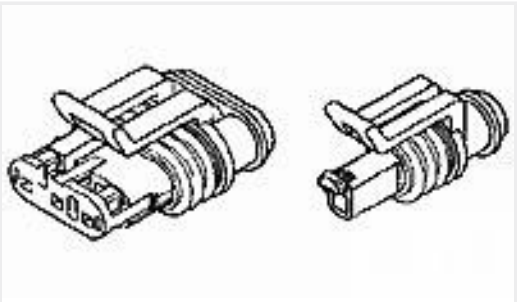


TE Part #282087-1
AMP SUPERSEAL 1.5 SERIES 3P PL



TE Part #5-1393302-8
V23134A1052C643-EV-CBOX



TE Part #F75818-000
RNF-100-MINI-SPL-1/4-BK

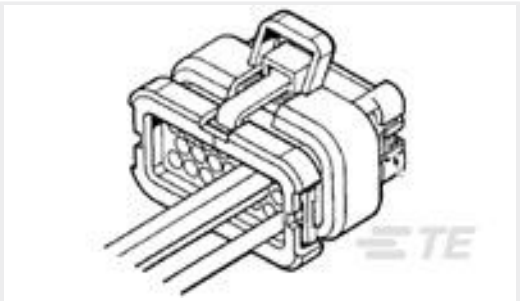

TE Part #770680-2
23POS,AMPSEAL,SOC HSG ASSY,SLD, COD 2



TE Part #CAT-T319-CH8172
TH/.025 CONNECTOR SYSTEM, HOUSING



TE Part #1-1418463-9
2POS MOS REC SEALED COD A

Documents

- CAD Files
- 3D PDF
- 3D
- Customer View Model
- ENG_CVM_CVM_175448-6_N1.2d_dxf.zip
- English
- Customer View Model



[ENG_CVM_CVM_175448-6_N1.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_175448-6_N1.3d_stp.zip](#)

English

3D PDF

English

Customer View Model

[ENG_CVM_175448-6_N3.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_175448-6_N3.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_175448-6_N3.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Instruction Sheets

HYBRID I/O CONNECTOR

English

Customer Manual (non U.S.)

English

HYBRID I/O CONNECTOR

English

Customer Manual (non U.S.)

English