


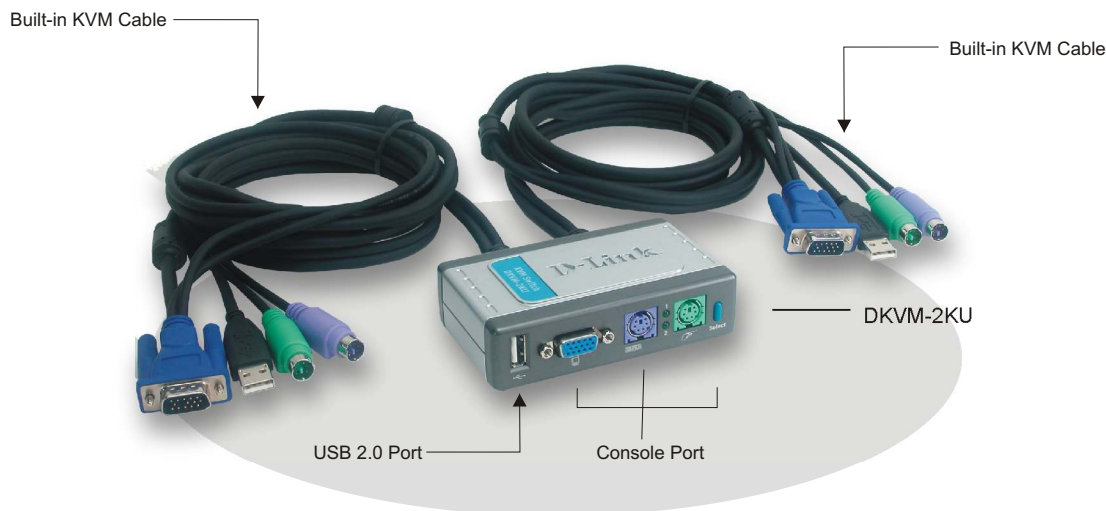

## Mini KVM Switch Kit With USB Port for 2 PCs

*Includes KVM Switch and 2 Sets of Built-in Cables & USB 2.0 Port*

The DKVM-2KU 2-port mini KVM (Keyboard, Video and Mouse) switch kit is a cost effective kit for home and office users. This double function kit allows you to easily control 2 different PCs from a single set of keyboard, mouse, and VGA monitor; and to share a USB device with 2 PCs. It includes a 2-port KVM switch, a USB 2.0 port built into the switch, and 2 sets of built-in cables for ready connection to 2 PCs. The switch provides many easy-to-use features and is perfect for home and the small business.

### Cost-effective for PC Users

If you have 2 PCs and need to use them at the same time, the DKVM-2KU saves you the money and space by allowing you to control your 2 computers from a set of keyboard, monitor and mouse. Or, you may have a better, bigger monitor and want to connect both PCs to it, the DKVM-2KU allows you to do this. 2 sets of cables are attached to the KVM switch ready for use, dispensing you of the need to prepare separate cables and connect them to the switch.

### Versatile Functions

The DKVM-2KU utilizes advanced microprocessor emulation to intelligently manage each KVM port. This allows simultaneous boot-up of all attached PCs. Auto scan, audible feedback, and keyboard "Hot Keys" make the DKVM-2KU simple to use and manage. There is also a control button located on the front panel that allows you to switch between the PCs.

### Status Save and High Resolution Support

The DKVM-2KU supports VGA, SVGA, and MultiSync monitors at up to 2048 x 1536 resolution at 72Hz refresh rate. Support for Microsoft IntelliMouse is provided.

### USB 2.0 Port to Share USB Devices

A USB 2.0 port is built into this KVM switch to allow connection to a USB-supported device or a USB hub. This allows you to share your USB printer, scanner, card reader or other devices among the 2 connected PCs. This USB port is also backward compatible with USB 1.1 devices. By connecting this USB port to a USB hub, you can also share more than 1 USB device with your 2 PCs. In the Auto Scan mode, the USB device switching will come with the computer scan sequence.

### Features

- 2 KVM ports to control of 2 computers from a single set of keyboard, monitor and mouse
- Built-in USB 2.0 port to share a USB device between the 2 PCs
- Saves desktop space, cost
- Auto scan mode sequences through PCs
- Audible feedback for confirmation while switching between PCs
- Front panel LED indicators for selected PC
- Switching between PCs using front panel SELECT button or Hot Key command
- Supports SVGA, VGA, and multi-sync monitors
- Video resolutions up to 2048 x 1536
- Successfully tested with following mice: Microsoft IntelliMouse, IntelliMouse with IntelliEye, and IntelliMouse Explorer; Logitech FirstMouse+, Logitech MouseMan+

# DKVM-2KU

## Technical Specifications

### Console Connectors (connect to keyboard, mouse, monitor)

- Keyboard connector: mini DIN-6 PIN female
- Mouse connector: mini DIN-6 PIN female
- Monitor connector: HD 15 PIN female

### KVM & USB Cables With Connectors (connect to computers)

- 2 cables each 1.8 meter (6 feet) long attached to KVM switch
- 2 keyboard connectors: mini DIN-6 PIN male
- 2 mouse connectors: mini DIN-6 PIN male
- 2 monitor connectors: HD 15 PIN male
- 2 USB Type A connectors

### USB Port Standard

USB 2.0

### Diagnostic LEDs

2 port LEDs for 2 connected PCs

### PC Selection (Manually switching back and forth between 2 PCs)

- Through Push buttons
- Through Hot Key
- Switching confirmation: buzzer sound

## Physical & Environmental

### Power Voltage

5V 1A

### Power Input

From PC's PS2 port, no external power adapter required

### Power Consumption

5V 70mA

### Dimensions

104 x 62 x 28 mm (KVM switch only)

### Weight

570 grams (KVM switch & 2 sets of KVM & USB cables)

### Operating Temperature

0° to 40 °C

### Storage Temperature

-20° to 60 °C

### Operating Humidity

0% to 80%

### Storage Humidity

0% to 80%


### Emission (EMI)

- FCC Class B
- CE Class B
- C-Tick

### Box Includes

- DKVM-2KU switch with 2 built-in sets of 1.8 m (6 ft) KVM cables
- Quick Installation Guide

## KVM Switch

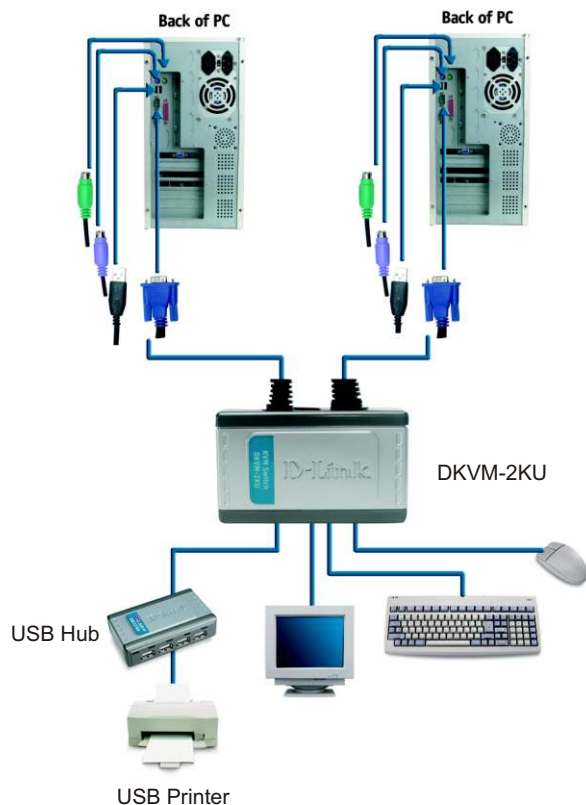

ACN 052 202 838

## Ordering Information

### DKVM-2KU

2-port mini KVM switch kit with built-in USB port  
Worldwide packaging (multi-lingual)

# D-Link®

Specifications subject to change without prior notice.  
D-Link is a registered trademark of D-Link Corporation/D-Link System Inc. All other trademarks belong to their proprietors.

|                     |                       |                       |
|---------------------|-----------------------|-----------------------|
| <b>U.S.A</b>        | TEL: 1-949-788-0805   | FAX: 1-949-753-7033   |
| <b>Canada</b>       | TEL: 1-905-8295033    | FAX: 1-905-8295095    |
| <b>Europe</b>       | TEL: 44-20-8731-5555  | FAX: 44-20-8731-5511  |
| <b>Germany</b>      | TEL: 49-6196-77990    | FAX: 49-6196-7799300  |
| <b>France</b>       | TEL: 33-1-30238688    | FAX: 33-1-30238689    |
| <b>Benelux</b>      | TEL: 31-10-282-1445   | FAX: 31-10-282-1331   |
| <b>Italy</b>        | TEL: 39-2-2900-0676   | FAX: 39-2-2900-1723   |
| <b>Iberia</b>       | TEL: 34-93-4090770    | FAX: 34-93-4910795    |
| <b>Sweden</b>       | TEL: 46-(0)8564-61900 | FAX: 46-(0)8564-61901 |
| <b>Norway</b>       | TEL: 47-22-309075     | FAX: 47-22-309085     |
| <b>Denmark</b>      | TEL: 45-43-969040     | FAX: 45-43-424347     |
| <b>Finland</b>      | TEL: 358-9-2707-5080  | FAX: 358-9-2707-5081  |
| <b>Singapore</b>    | TEL: 65-6774-6233     | FAX: 65-6774-6322     |
| <b>Australia</b>    | TEL: 61-2-8899-1800   | FAX: 61-2-8899-1868   |
| <b>Japan</b>        | TEL: 81-3-5434-9678   | FAX: 81-3-5434-9868   |
| <b>China</b>        | TEL: 86-10-8518-2533  | FAX: 86-10-8518-2250  |
| <b>India</b>        | TEL: 91-22-652-6696   | FAX: 91-22-652-8914   |
| <b>Middle East</b>  | TEL: 9714-8834234     | FAX: 9714-8834394     |
| <b>Turkey</b>       | TEL: 90-212-335-2553  | FAX: 90-212-335-2500  |
| <b>Chile</b>        | TEL: 56-2-232-3185    | FAX: 56-2-232-0923    |
| <b>Brasil</b>       | TEL: 55-11-3094-2910  | FAX: 55-11-3094-2921  |
| <b>South Africa</b> | TEL: 27(0)1266-52165  | FAX: 27(0)1266-52186  |
| <b>Russia</b>       | TEL: 7-095-737-3389   | FAX: 7-095-737-3390   |
| <b>Taiwan</b>       | TEL: 886-2-2910-2626  | FAX: 886-2-2910-1515  |
| <b>D-Link Corp.</b> | TEL: 886-2-2916-1600  | FAX: 886-2-2914-6299  |



RECYCLABLE  
Rev. 01 (Aug. 2003)