

Technical data


WS81108

Thrust washer



Needle roller bearing, thrust needle roller bearing, inner ring

VISUAL (S)

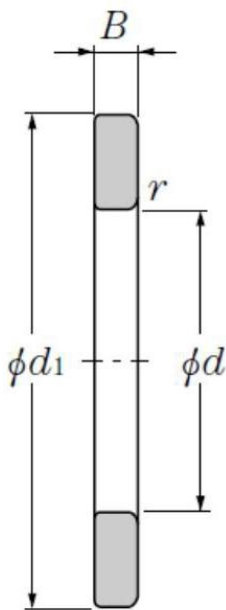

PRODUCT DEFINITION

Brand	NTN
d - Bore diameter of support washer IR - WS	40 mm
d1 - External diameter of support washer IR - WS	60 mm
B - Ring thickness	3,5 mm
rs - Min fillet radius	0,6 mm
Bearing ring (inner ring) WS mass	0,044 kg

PRODUCT PERFORMANCE

Tmin - Min operating temperature	-20 °C
----------------------------------	--------



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT PERFORMANCE

Tmax - Max operating temperature	120 °C
----------------------------------	--------

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
-----------	---------

Reference	WS81108
-----------	---------

Image	NRBWS_1.jpg, NRBWS_3.jpg
-------	--------------------------

