



## NT 40/1 TACT TE M \*GB 240V

The NT 40/1 Tact Te M is designed for the pickup of very large quantities of hazardous dusts, suitable for dust class M. It is robust yet highly mobile, featuring a 40 litre container.



## NT 40/1 TACT TE M \*GB 240V

### Technical data

<b>Order Number</b>	1.148-355.0	
<b>EAN code</b>	4054278483696	
<b>Air flow</b>	<b>l/s</b>	74
<b>Vacuum</b>	<b>mbar / kPa</b>	237 / 23,7
<b>Container capacity</b>	<b>l</b>	40
<b>Max. rated input power</b>	<b>W</b>	1380
<b>Standard nominal size</b>	35	
<b>Sound level</b>	<b>dB(A)</b>	68
<b>Weight</b>	<b>kg</b>	15,1
<b>Dimensions (L x W x H)</b>	<b>mm</b>	560 × 370 × 655


### Equipment

<b>Suction hose</b>	<b>m</b>	4	<b>Caster with brake</b>	■
<b>Filter bag</b>	Fleece		<b>Filter cleaning</b>	Tact Filter Clean
<b>Wet and dry floor tool</b>	<b>mm</b>	360	<b>Dust class</b>	M
<b>Crevice nozzle</b>	■			
<b>Connector for electric tools</b>	■			
<b>Automatic on/off control for electric power tools</b>	■			
<b>Antistatic system</b>	■			
<b>Eco filter system</b>	■			
<b>Flat pleated filter</b>	PES			
<b>Sturdy bumper</b>	■			
<b>Safety class</b>	I			

■ Included in delivery.

# ACCESSORIES FOR NT 40/1 TACT TE M \*GB 240V 1.148-355.0

**KÄRCHER**

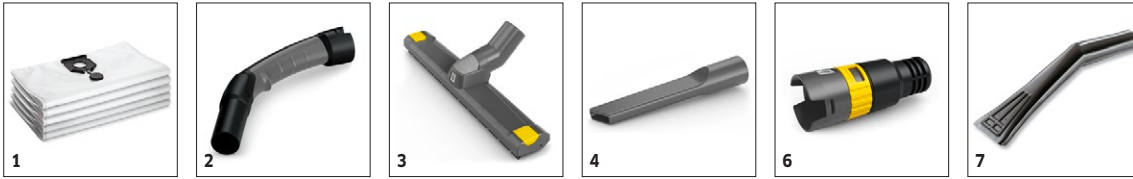

		Order Number	Quantity	ID	Length	Width	Price	Description	
<b>Fleece filter bags (3 ply)</b>									
Filter bags-fleece 5 piece 40-50 Liter	1	2.889-155.0	5 piece(s)						■
<b>Plastic bend</b>									
Elbow complete packaged NW35 2K	2	2.889-168.0	1 piece(s)	ID 35					■
<b>All-purpose nozzles (wet/dry)</b>									
Floor tool packaged NW35 360mm	3	2.889-152.0	1 piece(s)	ID 35		360 mm			■
<b>Crevice nozzles</b>									
Crevice nozzle wet and dry packaged NW35	4	2.889-159.0	1 piece(s)	ID 35	225 mm				■
<b>Suction tubes stainless steel</b>									
Set suction tube stainless steel NW35 55	5	2.889-192.0	1 piece(s)	ID 35	550 mm				■
<b>Adapter for electric power tools, clip on, el.</b>									
Sleeve electrically conducting packaged	6	2.889-151.0	1 piece(s)	ID 35					■
<b>Car cleaning nozzles</b>									
Car nozzle DN35	7	6.906-108.0	1 piece(s)	ID 35		90 mm		Angled, flat, plastic car vacuuming tool with about 90 mm working width. Only for NT vacuum cleaners.	□

■ Included in delivery. □ Available accessories.