

BPOC SERIES

IP20 BACKLIT LED PANELS



30-50W



up to
6000LM



IP20



Recycleable
Cardboard



4000K



Slim Design



5 Years
Warranty



Secure
Twist & Lock Connection



600x600



300x1200



600x1200



PRODUCT FEATURES

- Core panel is plug & play with ON/OFF function
- UV Stabilised Diffuser to prevent discoloration
- Smart Sensor upgrades available
- Optional Emergency Kits & Surface Mounting Kits
- Optional DALI, TRIAC Dimming, Casambi available



BPOC SERIES

IP20 BACKLIT LED PANELS



SPECIFICATIONS

600x600



300x1200



600x1200




Stock Code	0696-078	0297-157	0029-484
Part Code	BPOC-6060	BPOC-30120	BPOC-60120
Input Voltage	220~240VAC	220~240VAC	220~240VAC
Output Voltage	9-42VDC	9-42VDC	34-58VDC
Output Current	750mA	750mA	1050mA
Wattage	30W	30W	50W
Lumens	3600LM	3600LM	6000LM
Power Factor	0.9	0.9	0.9
Efficacy (lm/W)	120LM/W	120LM/W	120LM/W
CRI	>80	>80	>80
CCT (K)	4000K	4000K	4000K
Beam Angle	100°	100°	100°
UGR	<19	<19	<19
Diffuser - TP(a)	UV Stabilised Polycarbonate	UV Stabilised Polycarbonate	UV Stabilised Polycarbonate
IP Rating	IP20	IP20	IP20
Powder Coating	White RAL9003	White RAL9003	White RAL9003
Operating Temperature	-20°C +40°	-20°C +40°	-20°C +40°
Weight	1.3KG	1.35KG	2.7KG
Dimensions (H * W * D)	595 x 595 x 32mm	295 x 1195 x 32mm	595 x 1195 x 32mm

*TP(a) = suitable for escape routes (Building Regulations Part B), exceeds TP(b) fire performance.

ACCESSORIES


SURFACE MOUNTING KIT

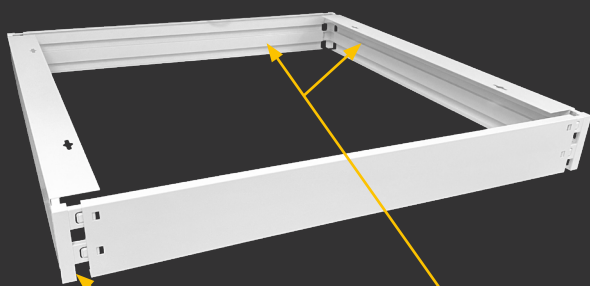

Modular Corner System

Reinforced Brackets

EMERGENCY KIT

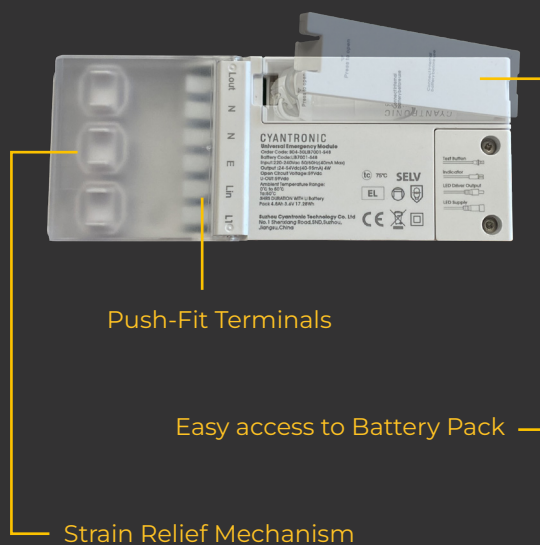

COMPATIBILITY

- Mains Dimming (Triac)
- 0-10V Dimming
- 1-10V Dimming



CASAMBI



SILVAIR

