

 

# branching module FRM-Y-D-MINI

Part number: 542184  
Classic

FESTO

Pneumatic manifold with 4 connections.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

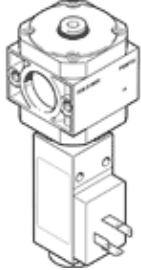

## Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0 ... 12 bar
Standard nominal flow rate in main flow direction 1->2	3,300 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Storage temperature	-10 ... 60 °C
Air purity class at output	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	507 g
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 4	G1/4
Materials note	Free of copper and PTFE Conforms to RoHS
Material housing	Aluminium die cast