

Datasheet

RS Pro Grey 6 A Grey Wall Switch Rocker Surface 5 mm, 1 Way Screwed Matte, 1 Gang BS Standard 86.5mm Not Illuminated IP20

RS Stock No: **668-3695**



Product Details


RS Pro 1-gang rocker surface light switch in grey colour, is made from corrosion-resistant matte MetalClad steel for long life durability. This IP20 rated switch has a 6 A current rating and 5 mm faceplate depth. It measures 86.5 x 86.5 mm. The switch has 1-way screw termination type. It is suitable for industrial, commercial and workshop applications. The switch meets BS3676 standards.

Features and Benefits



- Made from mild steel
- Suitable for industrial, commercial and workshop applications
- IP20 rated

**Specifications:**


Colour Shade	Grey
Colour	Grey
Current Rating	6 A
Faceplate Depth	5 mm
Faceplate Fixing	Screwed
Finish	Matte
Fixing Standard	BS Standard
Height	22 mm
Illumination	Not Illuminated
IP Rating	IP20
Length	86.5 mm
Material	Metalclad Steel
Minimum Box Depth	25 mm
Mount Type	Surface
Number of Gangs	1
Number of Poles	3
Number of Ways	1
Standards Met	BS3676; ASTA Approved
Switch Type	Rocker
Termination Type	Screw
Width	86.5 mm

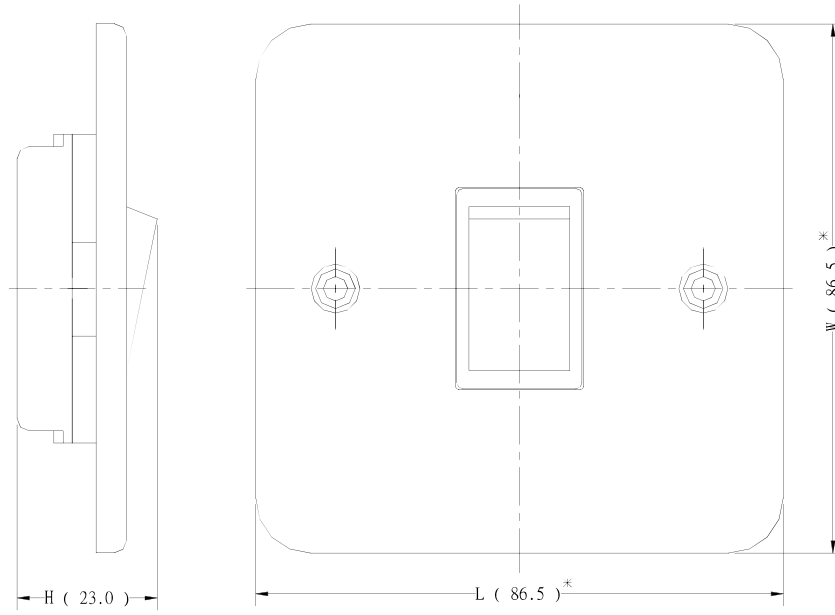


8181MA 外觀圖

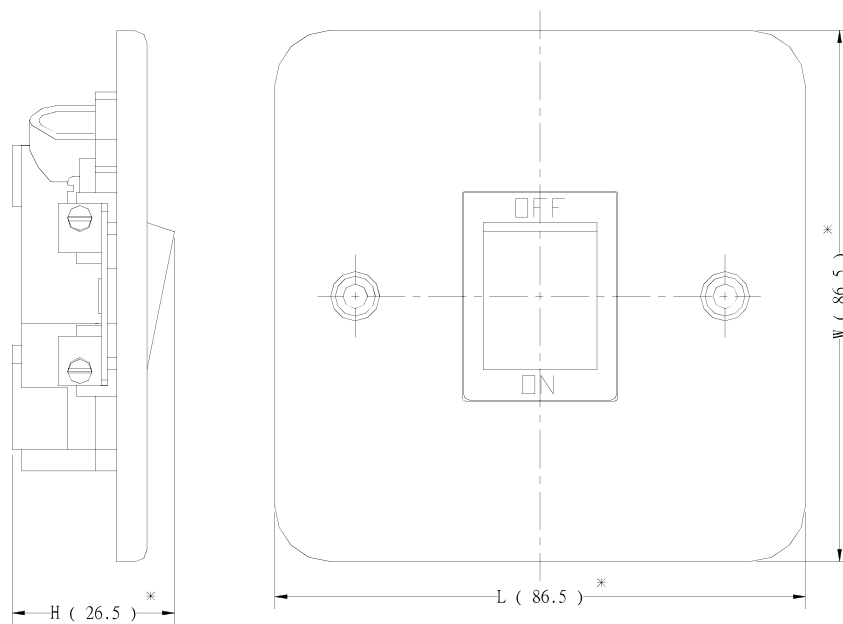
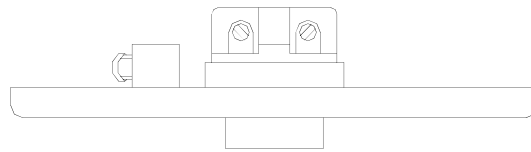


8184MA 成品外觀圖

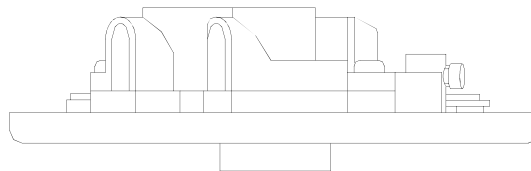



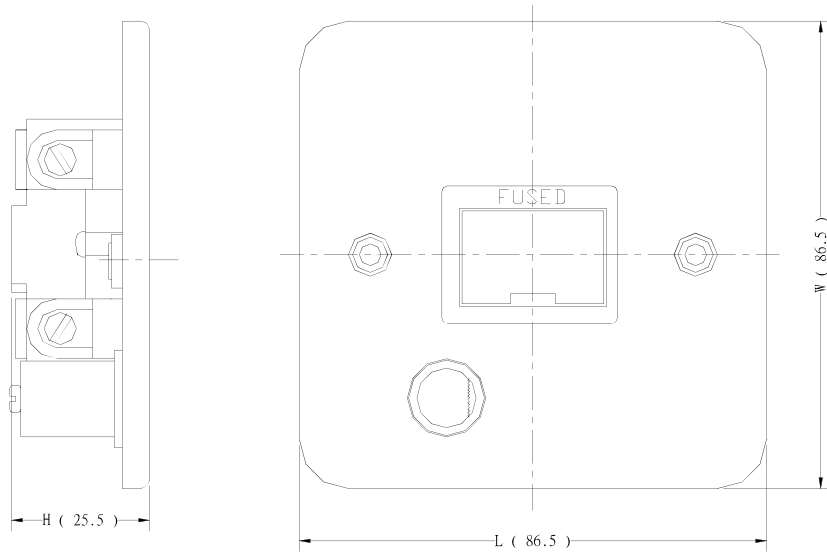


1893SMA 外觀圖

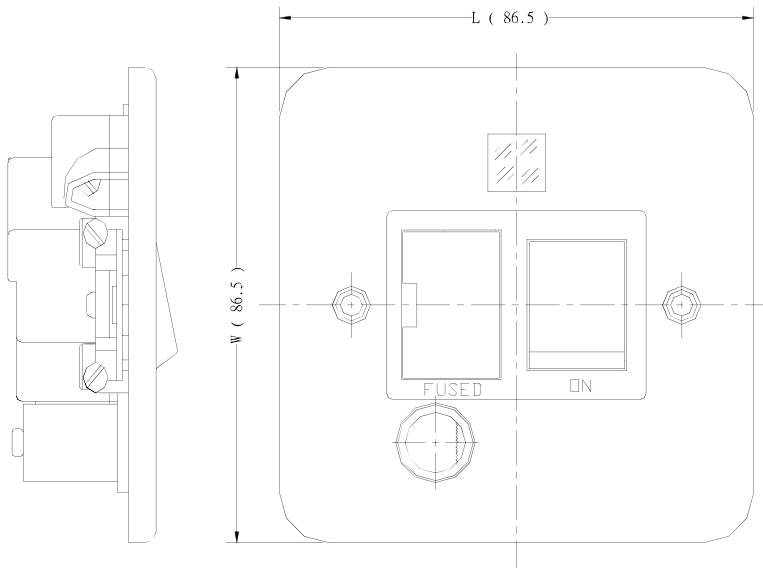
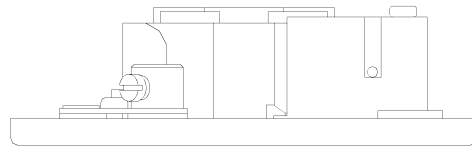


2893NSMA 外觀圖

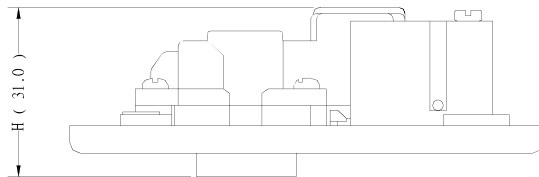


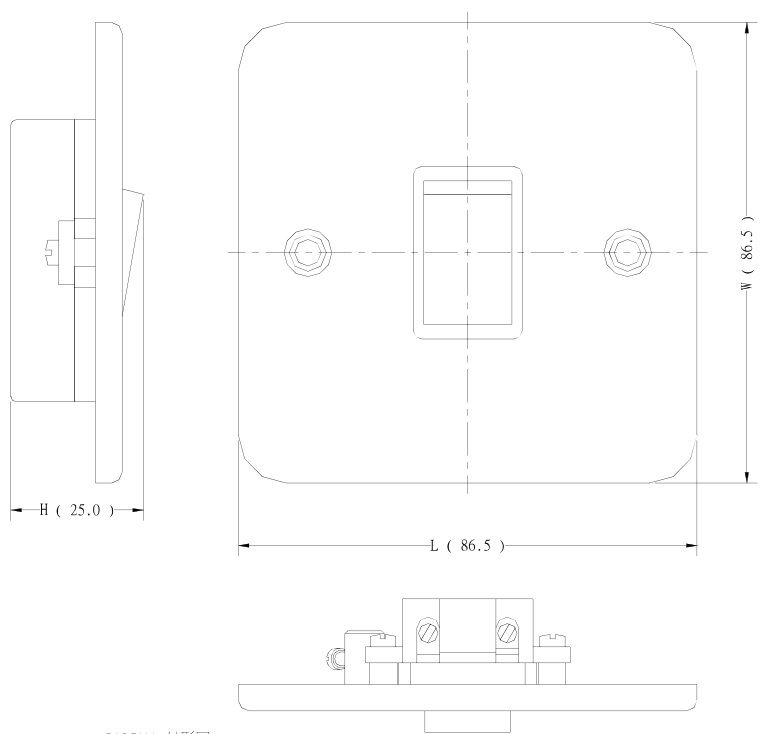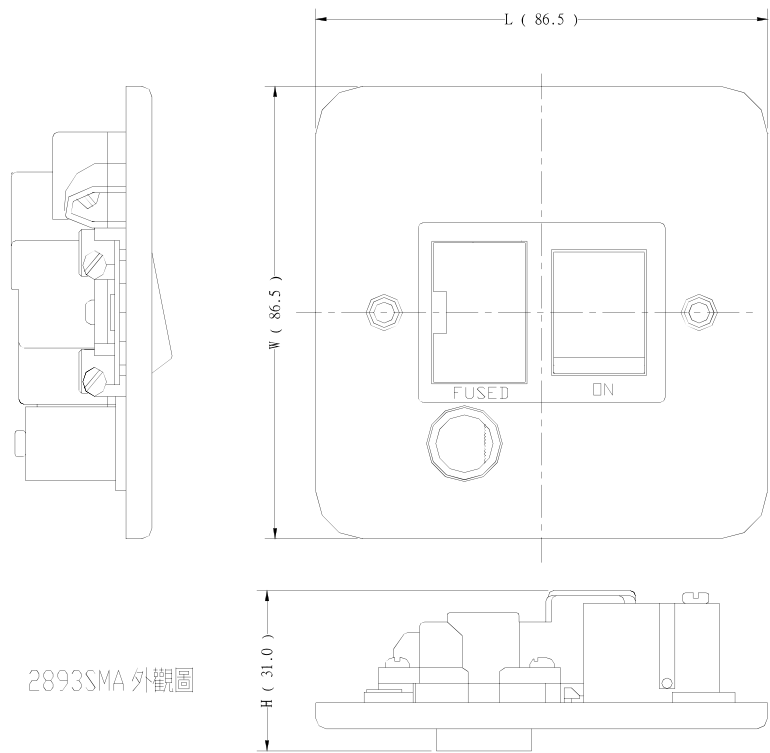

8103MA 外形圖

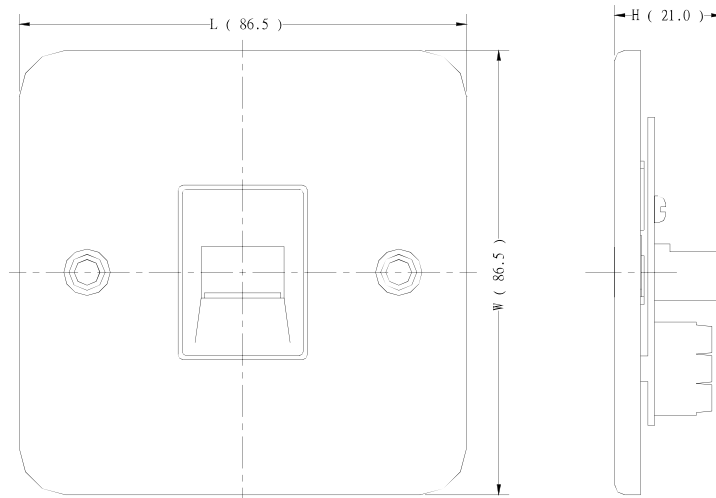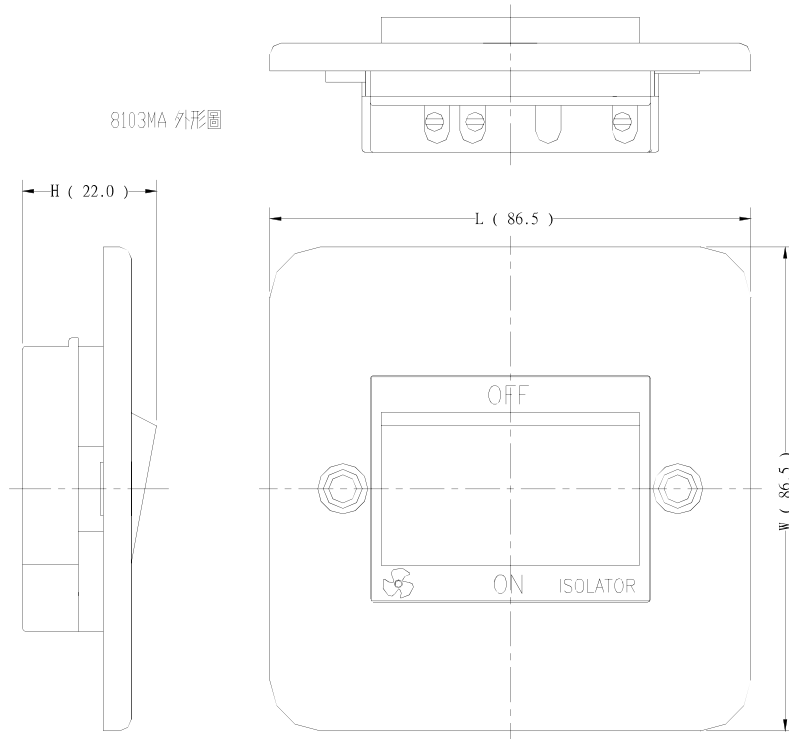

7183S/MA 成品圖

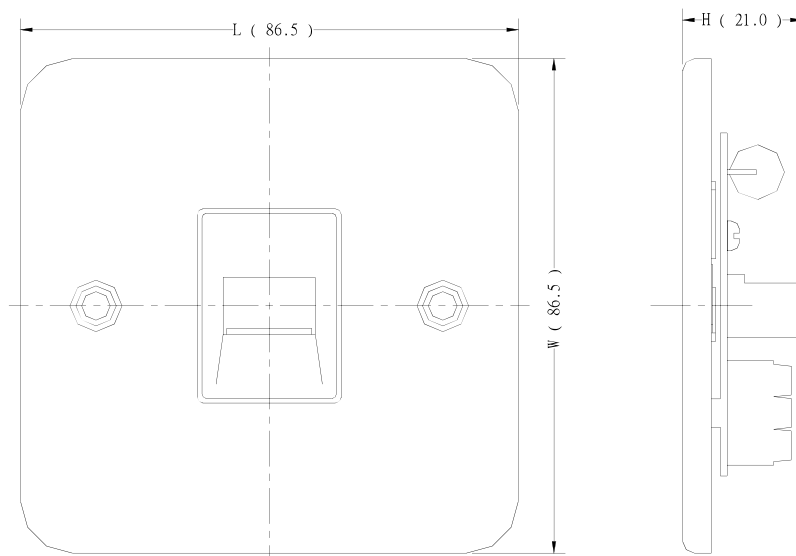

7183M/MA 成品圖

Part No.	L	W	H
8184/MA	86.5	86.5	26.5
1893S/MA	86.5	86.5	25.5
8181/2W/MA	86.5	86.5	23.0
2893S/MA	86.5	86.5	31.0
2893NS/MA	86.5	86.5	31.0
7183M/MA	86.5	86.5	21.0
7183S/MA	86.5	86.5	21.0
8102/MA	86.5	86.5	25.0
8103/MA	86.5	86.5	22.0